

Modular plastic range

Non-illuminated extended pushbuttons



MP3-10R

1SFC151006V0001



MP3-20Y

1SFC151028V0001



MP3-10W

1SFC151013V0001



MP3-10C

1SFC151383V0001



MP4-10G

1SFC151012V0001



MP4-10L


1SFC151019V0001



MP4-10B

1SFC151011V0001

| Operator | Bezel | Type | Order code | Pkg qty | Weight (1 pce) kg |
|-------------------|----------------|---------|-----------------|---------|-------------------|
| Momentary | | | | | |
| ● Red | Black plastic | MP3-10R | 1SFA611102R1001 | 10 | 0.016 |
| | Chrome plastic | MP3-20R | 1SFA611102R2001 | 10 | 0.016 |
| | Chrome metal | MP3-30R | 1SFA611102R3001 | 10 | 0.026 |
| ● Green | Black plastic | MP3-10G | 1SFA611102R1002 | 10 | 0.016 |
| | Chrome plastic | MP3-20G | 1SFA611102R2002 | 10 | 0.016 |
| | Chrome metal | MP3-30G | 1SFA611102R3002 | 10 | 0.026 |
| ● Yellow | Black plastic | MP3-10Y | 1SFA611102R1003 | 10 | 0.016 |
| | Chrome plastic | MP3-20Y | 1SFA611102R2003 | 10 | 0.016 |
| | Chrome metal | MP3-30Y | 1SFA611102R3003 | 10 | 0.026 |
| ● Blue | Black plastic | MP3-10L | 1SFA611102R1004 | 10 | 0.016 |
| | Chrome plastic | MP3-20L | 1SFA611102R2004 | 10 | 0.016 |
| | Chrome metal | MP3-30L | 1SFA611102R3004 | 10 | 0.026 |
| ○ White | Black plastic | MP3-10W | 1SFA611102R1005 | 10 | 0.016 |
| | Chrome plastic | MP3-20W | 1SFA611102R2005 | 10 | 0.016 |
| | Chrome metal | MP3-30W | 1SFA611102R3005 | 10 | 0.026 |
| ● Black | Black plastic | MP3-10B | 1SFA611102R1006 | 10 | 0.016 |
| | Chrome plastic | MP3-20B | 1SFA611102R2006 | 10 | 0.016 |
| | Chrome metal | MP3-30B | 1SFA611102R3006 | 10 | 0.026 |
| ○ Clear | Black plastic | MP3-10C | 1SFA611102R1008 | 10 | 0.016 |
| | Chrome metal | MP3-30C | 1SFA611102R3008 | 10 | 0.026 |
| Maintained | | | | | |
| ● Red | Black plastic | MP4-10R | 1SFA611103R1001 | 10 | 0.016 |
| | Chrome plastic | MP4-20R | 1SFA611103R2001 | 10 | 0.016 |
| ● Green | Black plastic | MP4-10G | 1SFA611103R1002 | 10 | 0.016 |
| | Chrome plastic | MP4-20G | 1SFA611103R2002 | 10 | 0.016 |
| ● Yellow | Black plastic | MP4-10Y | 1SFA611103R1003 | 10 | 0.016 |
| | Chrome plastic | MP4-20Y | 1SFA611103R2003 | 10 | 0.016 |
| ● Blue | Black plastic | MP4-10L | 1SFA611103R1004 | 10 | 0.016 |
| | Chrome plastic | MP4-20L | 1SFA611103R2004 | 10 | 0.016 |
| ○ White | Black plastic | MP4-10W | 1SFA611103R1005 | 10 | 0.016 |
| ● Black | Black plastic | MP4-10B | 1SFA611103R1006 | 10 | 0.016 |
| | Chrome metal | MP4-30B | 1SFA611103R3006 | 10 | 0.026 |
| ○ Clear | Black plastic | MP4-10C | 1SFA611103R1008 | 10 | 0.016 |

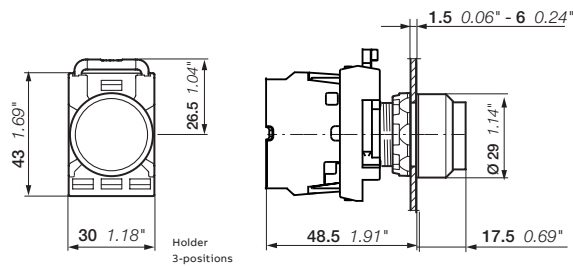

MP3, MP4
Dimensions (mm, inches)