

KC6 4-pole mini contactor relays – with flat pin connection

DC operated



KC6-22Z-F-01


KC6..F 4-pole mini-contactor relays are space optimized control products mainly used for control functions or for small loads up to 4 A.

These contactors are designed with 4 poles with various contact combinations:

- flat pin connection for plug-in wiring and shake proven connection
- control circuit: DC operated, low consumption coil (3.5 W at pull-in and at holding)
- hum-free coil
- contacts configurations 22 and 31 fulfill the requirements for Mechanically linked contacts acc. to annex L of IEC/EN 60947-5-1
- add-on auxiliary contact blocks for side mounting
- suitable for rail or wall mounting

Rated control circuit voltage U _c VDC	Type	Order code	Pkg qty	Weight (1 pce) kg
2 N.O. + 2 N.C. main poles				
12	KC6-22Z-F-07	GJH1213003R0227	10	0.170
24	KC6-22Z-F-01	GJH1213003R0221	10	0.170
48	KC6-22Z-F-16	GJH1213003R1226	10	0.170
110 ... 125	KC6-22Z-F-04	GJH1213003R0224	10	0.170
220 ... 240	KC6-22Z-F-05	GJH1213003R0225	10	0.170
3 N.O. + 1 N.C. main poles				
12	KC6-31Z-F-07	GJH1213003R0317	10	0.170
24	KC6-31Z-F-01	GJH1213003R0311	10	0.170
48	KC6-31Z-F-16	GJH1213003R1316	10	0.170
110 ... 125	KC6-31Z-F-04	GJH1213003R0314	10	0.170
220 ... 240	KC6-31Z-F-05	GJH1213003R0315	10	0.170
4 N.O. main poles				
24	KC6-40E-F-01	GJH1213003R0401	10	0.170
48	KC6-40E-F-16	GJH1213003R1406	10	0.170
110 ... 125	KC6-40E-F-04	GJH1213003R0404	10	0.170
220 ... 240	KC6-40E-F-05	GJH1213003R0405	10	0.170

Other types on request.

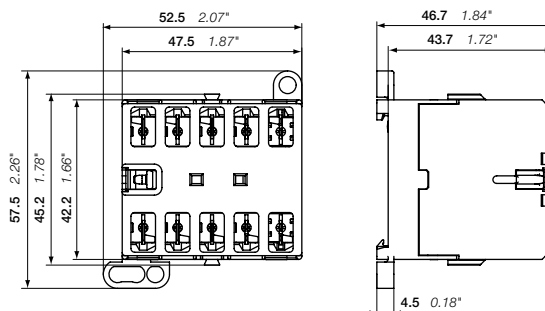

KC6

Main dimensions mm, inches