

KC6 4-pole interface mini contactor relays – with screw terminals DC operated



20DC21101/F0011

KC6-31Z

Description

KC6 4-pole interface mini-contactor relays are space optimized control products mainly used for control functions or for small loads up to 4 A.

These contactors are designed with:


- 4-poles with various contact combinations
- control circuit: DC operated
 - low coil consumption (1.4 ... 2.8 W at pull-in and at holding)
 - hum-free coil
- no auxiliary contact block permitted for mounting
- designed for rail or wall mounting

Ordering details

Rated control circuit voltage U_c V DC	Catalog number	Global code	Pkg qty	Weight (1 pce) kg
DC operation 24 V / 1.4 W				
24	KC6-31Z-1.4	GJH1213001R8311	10	0.175
24	KC6-40E-1.4	GJH1213001R8401	10	0.175
DC operation 17 ... 32 V / 2.4 W				
17 ... 32	KC6-31Z-2.4	GJH1213001R5311	10	0.175
17 ... 32	KC6-40E-2.4	GJH1213001R5401	10	0.175
DC operation 24 V / 1.7 W				
24	K6S-22Z-1.7	GJH1213001R7221	10	0.175
24	K6S-31Z-1.7	GJH1213001R7311	10	0.175
24	K6S-40E-1.7	GJH1213001R7401	10	0.175
DC operation 17 ... 32 V / 2.8 W				
17 ... 32	K6S-22Z-2.8	GJH1213001R7222	10	0.175
17 ... 32	K6S-31Z-2.8	GJH1213001R7312	10	0.175
17 ... 32	K6S-40E-2.8	GJH1213001R7402	10	0.175

Note: Other types on request

Main dimensions mm, inches

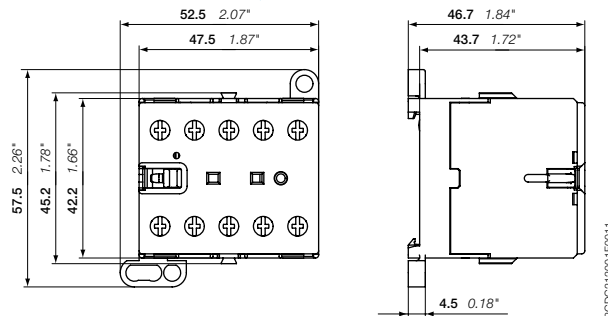

KC6

20DC212001/F0011