

K6 4-pole mini contactor relays – with flat pin connection AC operated



2DCD21100450011

K6-22Z-F

3

Description

K6 4-pole mini-contactor relays are space optimized control products mainly used for control functions or for small loads up to 4 A.

These contactors are designed with:


- flat pin connection for plug-in wiring and shake proven connection
- 4-poles with various contact combinations
- control circuit: AC operated
 - low coil consumption (3.5 VA at pull-in and at holding)
- hum-free coil
- add-on auxiliary contact blocks for side mounting
- for rail and wall mounting
- add-on auxiliary contact blocks for side mounting

Ordering details

Rated control circuit voltage U_c		Catalog number	Global code	Pkg qty	Weight (1 pce)
50 Hz	60 Hz				
V AC	V AC				kg
K6 4-pole mini contactor relays					
24	24	K6-22Z-F01	GJH1211003R0221	10	0.170
42	42	K6-22Z-F02	GJH1211003R0222	10	0.170
48	48	K6-22Z-F03	GJH1211003R0223	10	0.170
110 ... 127	110 ... 127	K6-22Z-F84	GJH1211003R8224	10	0.170
220 ... 240	220 ... 240	K6-22Z-F80	GJH1211003R8220	10	0.170
380 ... 415	380 ... 415	K6-22Z-F85	GJH1211003R8225	10	0.170
24	24	K6-31Z-F01	GJH1211003R0311	10	0.170
42	42	K6-31Z-F02	GJH1211003R0312	10	0.170
48	48	K6-31Z-F03	GJH1211003R0313	10	0.170
110 ... 127	110 ... 127	K6-31Z-F84	GJH1211003R8314	10	0.170
220 ... 240	220 ... 240	K6-31Z-F80	GJH1211003R8310	10	0.170
380 ... 415	380 ... 415	K6-31Z-F85	GJH1211003R8315	10	0.170
24	24	K6-40E-F01	GJH1211003R0401	10	0.170
42	42	K6-40E-F02	GJH1211003R0402	10	0.170
48	48	K6-40E-F03	GJH1211003R0403	10	0.170
110 ... 127	110 ... 127	K6-40E-F84	GJH1211003R8404	10	0.170
220 ... 240	220 ... 240	K6-40E-F80	GJH1211003R8400	10	0.170
380 ... 415	380 ... 415	K6-40E-F85	GJH1211003R8405	10	0.170

Note: Other types on request

Main dimensions mm, inches

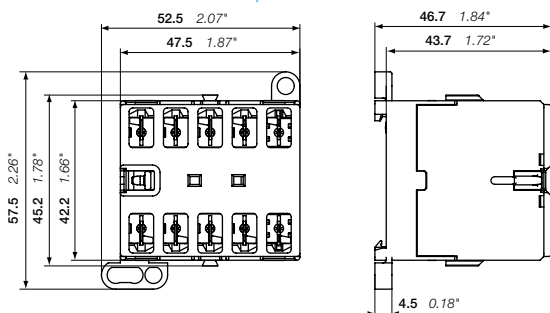

K6

2DCD212002F0011