

MCBs

Order Information



S281UC



S282UC

Characteristic B

Rated current (A)	Breaking capacity (kA)	S280UC-B	
		1 Pole	2 Poles
6	6	S281UC-B6	S282UC-B6
10		S281UC-B10	S282UC-B10
16		S281UC-B16	S282UC-B16
20		S281UC-B20	S282UC-B20
25		S281UC-B25	S282UC-B25


Characteristic C

Rated current (A)	Breaking capacity (kA)	S280UC-C		
		1 Pole	2 Poles	3 Poles
0.5	6	S281UC-C0.5	S282UC-C0.5	S283UC-C0.5
1		S281UC-C1	S282UC-C1	S283UC-C1
1.6		S281UC-C1.6	S282UC-C1.6	S283UC-C1.6
2		S281UC-C2	S282UC-C2	S283UC-C2
3		S281UC-C3	S282UC-C3	S283UC-C3
4		S281UC-C4	S282UC-C4	S283UC-C4
6		S281UC-C6	S282UC-C6	S283UC-C6
8		S281UC-C8	S282UC-C8	S283UC-C8
10		S281UC-C10	S282UC-C10	S283UC-C10
16		S281UC-C16	S282UC-C16	S283UC-C16
20		S281UC-C20	S282UC-C20	S283UC-C20
25		S281UC-C25	S282UC-C25	S283UC-C25
32		S281UC-C32	S282UC-C32	S283UC-C32
40		4.5	S281UC-C40	S282UC-C40
50	S281UC-C50		S282UC-C50	S283UC-C50
63	S281UC-C63		S282UC-C63	S283UC-C63

MCBs

Dimensions (mm)

SH200 / S200M

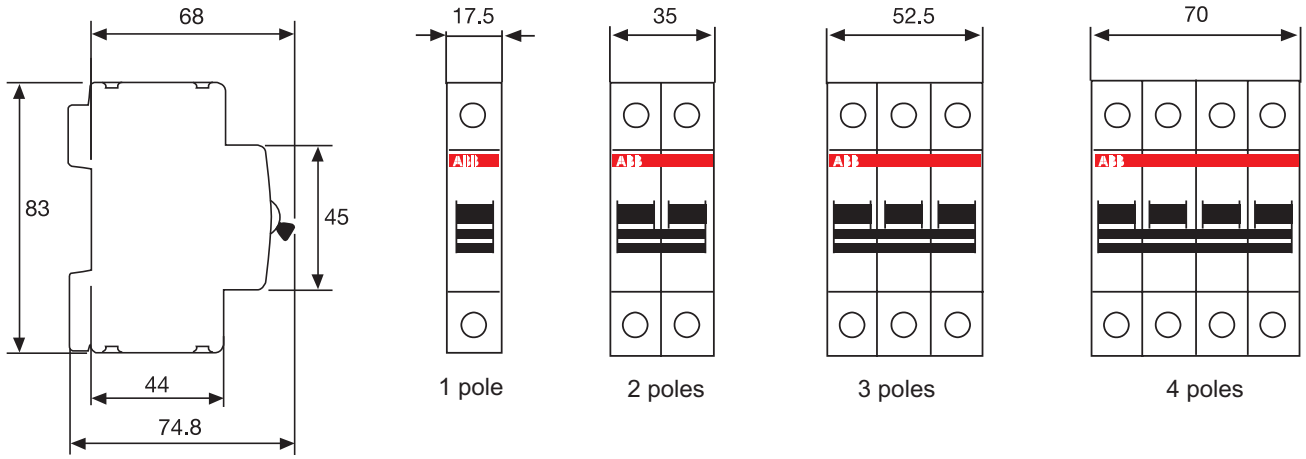

S280UC

