

Ordering information

Front operated switch-disconnectors

OTDC100...200US02



Switch-disconnectors OTDC_, UL-types, base mounting

Up to 1000 VDC

Including terminal bolt kit, the handle and shaft have to be ordered separately, see pages 18...19. OTDC100...200US02 types are equipped with a short circuit link.

OTDC100...200U02



OTDC100...200US11



OTDC100...200U11




Number of poles	Rated current [A] UL98B, 1000 V	Type	Order number	Delivery batch [pcs]	Weight/unit [kg]
Mechanism at the end of the switch, includes the short circuit link					
2	100	OTDC100US02	1SCA126155R1001	1	1.2
2	200	OTDC200US02	1SCA126121R1001	1	1.2
Mechanism at the end of the switch					
2	100	OTDC100U02	1SCA126184R1001	1	1.1
2	200	OTDC200U02	1SCA126123R1001	1	1.1
Mechanism between the poles, includes the short circuit link					
2	100	OTDC100US11	1SCA125437R1001	1	1.2
2	200	OTDC200US11	1SCA125436R1001	1	1.2
Mechanism between the poles					
2	100	OTDC100U11	1SCA123957R1001	1	1.1
2	200	OTDC200U11	1SCA123767R1001	1	1.1

Shafts and handles included as standard

Suitable for switches	Included shaft	Included handle	Included terminal bolts
OTDC100...250U_	-	-	M8x25

OTDC100US_, OTDC200US_

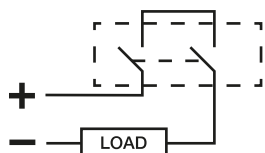

OTDC100U_, OTDC200U_

