



Transformers with CE Mark

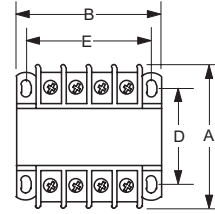


TC40501

Primary voltage - 240/480V, 230/460V, 220/440V
Secondary voltage - 120V, 115V, 110V

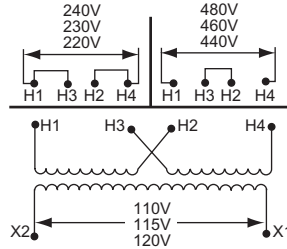

Top View

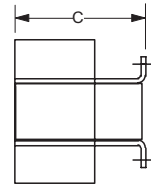

Side View



VA rating	Catalog number	List price	Output amps	Dimensions (inches • mm)					Mounting slots	Approx. wt. Lbs • kg
				A	B	C	D	E		
50	TC40501	\$ 55	0.43	3 • 86	3 • 76	3 • 76	2 1/2 • 64	2 1/2 • 64	203 X 460 • 5.1x11.7	3.5 • 1.6
75	TC40751	62	0.65	3 3/8 • 89	3 3/8 • 86	3 1/4 • 83	2 1/2 • 64	2 13/16 • 71	203 X 460 • 5.1x11.7	4.8 • 2.2
100	TC41001	72	0.87	3 1/2 • 92	3 3/4 • 95	3 1/2 • 89	2 1/2 • 64	3 1/8 • 79	203 X 460 • 5.1x11.7	5.9 • 2.7
150	TC41501	88	1.30	4 • 102	4 1/2 • 114	4 • 102	2 1/2 • 64	3 3/4 • 95	203 X 460 • 5.1x11.7	8.5 • 3.9
200	TC42001	101	1.74	4 1/2 • 114	4 1/2 • 114	4 • 102	3 1/2 • 81	3 3/4 • 95	203 X 460 • 5.1x11.7	10.6 • 4.8
250	TC42501	120	2.17	4 3/4 • 121	4 1/2 • 114	4 • 102	3 3/16 • 81	3 3/4 • 95	203 X 460 • 5.1x11.7	11.3 • 5.1
300	TC43001	130	2.61	5 1/4 • 133	4 1/2 • 114	4 • 102	3 3/4 • 95	3 3/4 • 95	203 X 460 • 5.1x11.7	13.2 • 6.0
350	TC43501	154	3.04	5 • 127	5 1/4 • 133	4 1/2 • 114	3 3/4 • 95	4 • 111	312 X 687 • 8x17.5	14.9 • 6.8
500	TC45001	168	4.35	6 • 152	5 1/4 • 133	4 1/2 • 114	4 • 102	4 3/8 • 111	312 X 687 • 8x17.5	21.0 • 9.5
750	TC47501	242	6.52	7 3/8 • 187	5 1/4 • 133	4 1/2 • 114	5 3/4 • 146	4 3/8 • 111	312 X 687 • 8x17.5	29.8 • 13.6

Note: No integral fusing capability. Supplied with touch-safe terminal covers installed.




TC2050F

Primary voltage - 120/240V
Secondary voltage - 24V

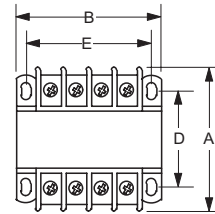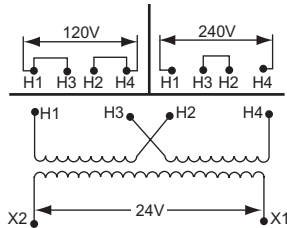

Top View

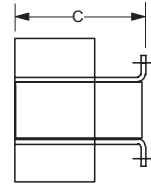

Side View

VA rating	Catalog number	List price	Output amps	Dimensions (inches • mm)					Mounting slots	Approx. wt. Lbs • kg
				A	B	C	D	E		
50	TC2050F	\$ 57	2.08	3 1/4 • 83	3 • 76	3 • 76	2 1/4 • 57	2 1/2 • 64	203 X 460 • 5.1x11.7	3.4 • 1.6
75	TC2075F	64	3.13	3 1/4 • 83	3 3/8 • 86	3 1/4 • 83	2 1/4 • 57	2 13/16 • 71	203 X 460 • 5.1x11.7	4.2 • 1.9
100	TC2100F	76	4.17	3 • 92	3 3/4 • 95	3 1/2 • 89	2 1/2 • 64	3 • 79	203 X 460 • 5.1x11.7	5.9 • 2.7
150	TC2150F	101	6.25	4 5/8 • 102	4 3/4 • 114	4 1/2 • 102	2 1/2 • 64	3 3/8 • 95	203 X 460 • 5.1x11.7	8.5 • 3.9
200	TC2200F	114	8.33	4 3/8 • 111	4 1/2 • 114	4 • 102	2 13/16 • 71	3 3/4 • 95	203 X 460 • 5.1x11.7	10.0 • 4.6
250	TC2250F	125	10.42	4 3/4 • 121	4 1/2 • 114	4 • 102	3 3/16 • 81	3 3/4 • 95	203 X 460 • 5.1x11.7	11.3 • 5.1
300	TC2300F	139	12.50	5 1/8 • 130	4 1/2 • 114	4 • 102	3 3/16 • 95	3 3/4 • 95	203 X 460 • 5.1x11.7	13.2 • 6.0
350	TC2350F	161	14.58	5 • 127	5 1/4 • 133	4 1/2 • 114	3 3/4 • 95	4 • 111	312 X 687 • 8x17.5	14.9 • 6.8
500	TC2500F	179	20.83	5 1/2 • 140	5 1/4 • 133	4 1/2 • 114	4 3/4 • 108	4 3/8 • 111	312 X 687 • 8x17.5	19.2 • 8.7
750	TC2750F	267	31.25	7 1/2 • 187	5 1/4 • 133	4 1/2 • 114	5 1/4 • 146	4 3/8 • 111	312 X 687 • 8x17.5	29.8 • 13.6

Note: No integral fusing capability. Supplied with touch-safe terminal covers installed.