


# Approximate dimensions Non-combination starters

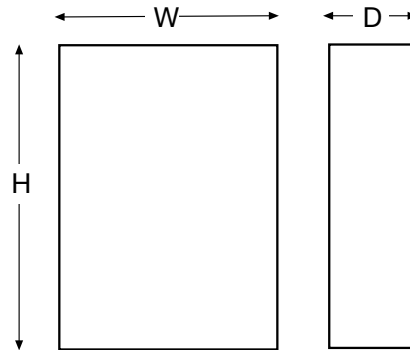

## IEC and NEMA starters

### Non reversing and reversing

Contactor Size	Enclosure Type	H (in)	H (mm)	W (in)	W (mm)	D (in)	D (mm)
AF09-AF30, AFN00-AFN1	1, 3R, 4, 4X, 12	12	300	12	300	6	150
AF50-AF75, AFN3		16	400	12	300	8	200
AF110		24	600	20	500	10	250
AF145-AF185, AFN4		36	900	30	760	10	250
AF210-AF300		48	1200	36	900	12	300
AF400-AF460		48	1200	36	900	16	400
AF580-AF750		60	1500	60	1500	18	449

### Two speed 1 winding & 2 winding

AF09-AF30	1, 3R, 4, 4X, 12	16	400	12	300	8	200
AF50-AF75		20	500	16	400	8	200
AF110		24	600	20	500	10	250
AF145-AF185		36	900	30	760	10	250
AF210-AF300		48	1200	36	900	12	300
AF400-AF460		48	1200	36	900	16	400
AF580-AF750		60	1500	60	1500	18	449

## Enclosure accessories for non-combination and combination controllers

Description	Catalog number
12Hx16D Floormount Kit	RC-FSK1212C
12Hx16D Floormount Kit	RC-FSK1216C
12Hx12D Floormount Kit Type 304 SS	RC-FSK12124
12Hx12D Floormount Kit Type 304 SS	RC-FSK12164
Padlock lockout carbon steel 1)	RC-WMPADRCS
Padlock lockout stainless steel 1)	RC-WMPADR6
Wallmount Bracket Kit	RC-2508.200
Wallmount Bracket Kit Type 304 SS	RC-2433.000

*Exact dimensions can be obtained using the on line configurator*

1) Used on enclosures below 36" in height.