




Handles


for 16A – 125A non-fusible disconnect switches
Base & DIN rail mounted



OHBS3_

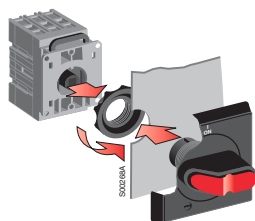

OHBS2_

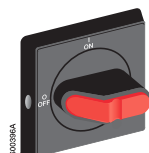

OZ331_B



OZ371PB



OHBS_



SS handles



OHBS2PJEH

Selector handles — for use with shafts (□ 6 x 6 mm) base-mount switches

NEMA type	IEC type	Color	Marking	Defeatable	Padlockable	Dim. (mm ²)	Catalog number	List price
All marked both O/I & Off/On								
1	IP54	Blk	O/I & OFF/ON	—	Yes	48	OHBS3AH1 ^①	
1	IP54	Red/Yel	O/I & OFF/ON	—	Yes	48	OHYS3AH1 ^①	
1, 3R, 12	IP65	Blk	O/I & OFF/ON	Yes	Yes	65	OHBS2AJ	
1, 3R, 12	IP65	Grey	O/I & OFF/ON	Yes	Yes	65	OHGS2AJ	
1, 3R, 12	IP65	Red/Yel	O/I & OFF/ON	Yes	Yes	65	OHYS2AJ	
1, 3R, 12	IP65	Blk	I / O / II	Yes	Yes	65	OHBS2AJE011	
1, 3R, 12	IP65	Red/Yel	I / O / II	Yes	Yes	65	OHYS2AJE011	
1, 3R, 12	IP65	SS HASP	O/I & OFF/ON	Yes	Yes	65	OHBS2AJEH	

Round Padlockable handles base-mount switches

Padlockable in 0-position, max 3 padlocks with max 8 mm hasp diameter.

NEMA type	IEC type	Color	Marking	Defeatable	Padlockable	Dim. (mm ²)	Catalog number	List price
NEMA 4X	IP65	Black	OFF/ON	Yes	Yes	66x66	OZ331PB	
NEMA 4X	IP65	Red/Yel	OFF/ON	Yes	Yes	66x66	OZ331PRY	
NEMA 4X	IP69K	Black	O/I & OFF/ON	Yes	Yes	66x66	OZ331P67B	
NEMA 4X	IP69K	Red/Yel	O/I & OFF/ON	Yes	Yes	66x66	OZ331P67RY	
Handles with door coupling in ON-position								
NEMA 4X	IP65	Black	OFF/ON	No	Yes	66x66	OZ371PB	
NEMA 4X	IP65	Red/Yel	OFF/ON	No	Yes	66x66	OZ371PRY	

Selector handles, Door mounted switches

NEMA type	IEC type	Color	Marking	Defeatable	Padlockable	Dim. (mm ²)	Catalog number	List price
All marked both O/I & Off/On								
Snap-on mounting — for use on OT16FT3 – OT40FT3								
1	IP54	Blk	O/I & OFF/ON	—	Yes	48	OHBS3PH	
1	IP54	Red/Yel	O/I & OFF/ON	—	Yes	48	OHYS3PH	
1, 3R, 12	IP65	Blk	O/I & OFF/ON	—	Yes	65	OHBS2PJ	
1, 3R, 12	IP65	Red/Yel	O/I & OFF/ON	—	Yes	65	OHYS2PJ	
1, 3R, 12	IP65	SS HASP	O/I & OFF/ON	—	Yes	65	OHBS2PJEH	

Screw mounting — for use on OT16FT3 – OT100FT3

NEMA type	IEC type	Color	Marking	Defeatable	Padlockable	Dim. (mm ²)	Catalog number	List price
1	IP54	Blk	O/I & OFF/ON	—	Yes	48	OHBS3RH	
1	IP54	Red/Yel	O/I & OFF/ON	—	Yes	48	OHYS3RH	
1, 3R, 12	IP65	Blk	O/I & OFF/ON	—	Yes	65	OHBS2RJ ^②	
1, 3R, 12	IP65	Red/Yel	O/I & OFF/ON	—	Yes	65	OHYS2RJ ^②	

Pistol handles — for use with shafts (□ 6 x 6 mm) ^③ padlockable with three padlocks in OFF-position, door interlock in ON-position.

NEMA type	IEC type	Color	Marking	Defeatable	Padlockable	Shaft size (mm ²)	Catalog number	List price
1, 3R, 12	IP65	Black	O/I & Off/On	Yes	Yes	6	OHB45J6	
		Red/Yel	O/I & Off/On	Yes	Yes	6	OHY45J6	
		Black	O/I & Off/On	Yes	Yes	6	OHB65J6	
		Grey	O/I & Off/On	Yes	Yes	6	OHG65J6	
		Red/Yel	O/I & Off/On	Yes	Yes	6	OHY65J6	
		Black	O/I & Off/On	Yes	Yes	6	OHB80J6	
		Grey	O/I & Off/On	Yes	Yes	6	OHG80J6	
		Red/Yel	O/I & Off/On	Yes	Yes	6	OHY80J6	
1, 3R, 4, 4X, 12	IP66	Black	O/I & Off/On	Yes	Yes	6	OHB65L6	
		Red/Yel	O/I & Off/On	Yes	Yes	6	OHY65L6	
		Black	O/I & Off/On	Yes	Yes	6	OHB80L6	
		Red/Yel	O/I & Off/On	Yes	Yes	6	OHY80L6	
1, 3R, 4, 4X, 12	IP65	SS	O/I & Off/On	Yes	Yes	6	OHB65L6	
1, 3R, 12	IP65	Black	I / O / II	Yes	Yes	6	OHB65J6E011	
		Red/Yel	I / O / II	Yes	Yes	6	OHY65J6E011	
1, 3R, 4, 4x, 12	IP66	Black	I / O / II	Yes	Yes	6	OHB65L6E011	
		Red/Yel	I / O / II	Yes	Yes	6	OHY65L6E011	


① Not suitable for use with OT30F3, OT60F3, OT100F3

② Suitable for OT30, 60, 100FT as well


③ Plastic pistol grip handle with stainless steel hasp, add suffix EH. ex.: OHB65J6EH

Shafts


for 16A – 125A non-fusible disconnect switches
Base & DIN rail mounted

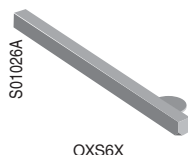

OXS6X__

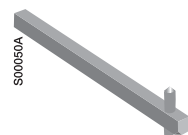

OXp6X__

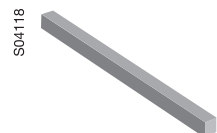

OXp6X__

Shafts — for use with OH selector handles (□ 6 x 6 mm)



Mounting depth^① in mm

Shaft length (mm)	OT16F3 OT25F3 OT40F3		OT63F3 OT80F3		OT30F3 OT60F3 OT100F3	Catalog number	List price
	OH_3_	OH_2_	OH_3	OH_2_	OH_2_		
85	105 – 125	90 – 110	125 – 140	110 – 125	100 – 125	OXS6X85	
130	150 – 170	135 – 155	170 – 185	155 – 170	145 – 170	OXS6X130	
180	200 – 220	185 – 205	220 – 235	205 – 220	195 – 220	OXS6X180	
250	270 – 290	255 – 275	290 – 305	275 – 290	265 – 290	OXS6X250	
330	350 – 370	335 – 355	370 – 385	355 – 370	345 – 370	OXS6X330	
455	475 – 495	460 – 480	495 – 510	480 – 495	470 – 495	OXS6X455	

Shafts — for use with pistol handles (□ 6 x 6 mm)



Mounting depth^① in mm

Shaft length (mm)	OT16F3 OT25F3 OT40F3	OT63F3 OT80F3	OT30F3 OT60F3 OT100F3	Catalog number	List price
150	155 – 170	175 – 185	160 – 185	OXp6X150	
170	175 – 190	195 – 205	180 – 205	OXp6X170	
265	270 – 285	290 – 300	275 – 300	OXp6X265	
400	405 – 420	425 – 435	410 – 435	OXp6X400	
500	505 – 520	525 – 535	510 – 535	OXp6X500	
700	705 – 720	725 – 735	710 – 735	OXp6X700	

Shafts — For round padlockable type handles. Shaft diameter 6 mm

Shaft length (mm)	suitable for switches	Catalog number	List price
60	OT16...100F	OX6X60	
85	OT16...100F	OX6X85	
105	OT16...100F	OX6X105	
115	OT16...100F	OX6X115	
130	OT16...100F	OX6X130	
155	OT16...100F	OX6X155	
200	OT16...100F	OX6X200	
300	OT16...100F	OX6X300	

① Mounting depth is the distance from the outside of door to the disconnect switch mounting plate. Shaft can be cut to desired length.