



Installation and Operation Instructions

A/Plastic Button Sensor

READ THESE INSTRUCTIONS BEFORE YOU BEGIN INSTALLATION


All ACI thermistors and RTD temperature sensors are both non-polarity and non-position sensitive. All thermistor and RTD type sensors are included with (2) 22 AWG stranded etched Teflon wires for making all of the proper connections.

■ TROUBLESHOOTING

Sensor reads 0 ohms or very low
 Sensor reads infinity or very high
 Erratic readings


Sensor or wires are shorted together
 Sensor or wires have been damage and are open
 Bad wire connections - Condensation or Moisture problem

■ PART DESCRIPTIONS

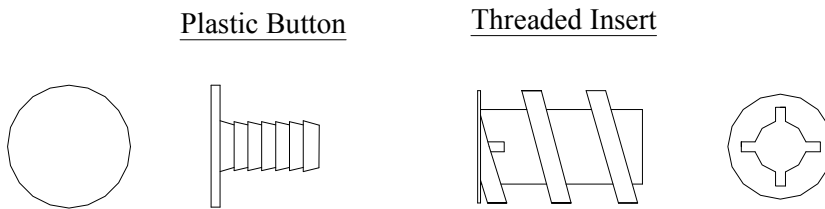

■ MOUNTING INSTRUCTIONS

Mounting in sheetrock is done through a 1/2" hole using regular hand tools as shown in **Figure 1**. Mounting into marble or rock can be done directly in a 1/4" hole without the threaded insert. If you have any further questions or comments regarding the Button sensor, please call ACI for technical assistance.

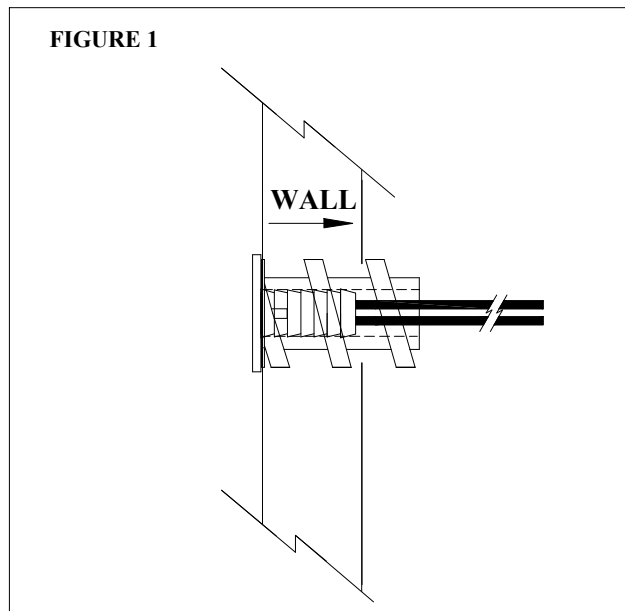

■ WEEE Directive

At the end of their useful life the packaging and product should be disposed of via a suitable recycle center. Do not dispose of with household waste. Do not burn.

