


ENTRY PLUGS

Polyamide PA6

1053
1052



Material: POLYAMIDE PA6 reinforced with fibreglass self-extinguishing class V0 (UL 94)
Temperature range: -20°C to +90°C (continuous)
Protection: IP 54
Colour: RAL 7035 light grey, RAL 9006 black

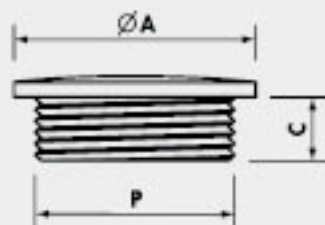

Metric thread M 1.5 pitch CEI EN 60423

Ref. Light Grey	P	∅ A (mm)	C (mm)	Quantity
1053M12	M12X1,5	15	6	100
1053M16	M16X1,5	20	6	100
1053M20	M20X1,5	25	7	100
1053M25	M25X1,5	30	7	100
1053M32	M32X1,5	37	9	50
1053M40	M40X1,5	47	9	30
1053M50	M50X1,5	58	10	20
1053M63	M63X1,5	72	12	10

Add to Ref. N for Black

Pg thread DIN 40 430 - Dimensions DIN 46 320

Ref. Light Grey	P	∅ A (mm)	C (mm)	Quantity Box/Bag
1052007	Pg 7	15	6	100
1052009	Pg 9	19	6	100
1052011	Pg11	22	7	100
1052013	Pg13,5	25	7	100
1052016	Pg16	27	7	100
1052021	Pg21	33	9	100/50
1052029	Pg29	44	9	50
1052036	Pg36	55	10	20
1052042	Pg42	62	10	10
1052048	Pg48	69	12	10

Add to Ref. N for Black