


MAXIblock® CABLE GLANDS

Polyamide PA6.6

1900/X



Material: POLYAMIDE PA6.6
 self-extinguishing class V2 (UL 94)
 Temperature range:
 -20°C to +90°C (continuous)
 Sealing ring: NEOPRENE® 50 sh A
 Protection: IP 68
 Colour: RAL 7035 light grey,

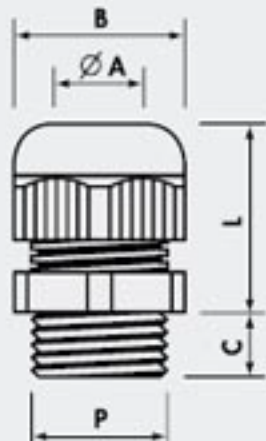

MAXIblock® standard factory fitted with locknuts with collar

Metric thread M 1.5 pitch CEI EN 60423 CEI EN 50262



Ref.	P	Fixing Hole Ø (mm)	Ø A min-max (mm)	B Spanner (mm)	C (mm)	L min-max (mm)	Quantity Box/Bag
1900.M12/X	M12X1,5	12,5	3,5- 7	15	8	18-22	100/10
1900.M16/X	M16X1,5	16,5	5 -10	19	8	22-27	100/10
1900.M20/X	M20X1,5	20,5	7 -13	25	9	24-30	50/10
1900.M25/X	M25X1,5	25,5	10 -17	30	10	28-39	30/10
1900.M32/X	M32X1,5	32,5	13 -21	36	10	33-44	20/10
1900.M40/X	M40X1,5	40,5	19 -28	46	10	36-45	15/5
1900.M50/X	M50X1,5	50,5	27 -35	55	12	43-52	10/5
1900.M63/X	M63X1,5	63,5	34 -45	66	12	45-55	5/5



Pg thread DIN 40 430



Ref.	P	Fixing Hole (mm)	Ø A min-max (mm)	B Spanner (mm)	C (mm)	L min-max (mm)	Quantity Box/Bag
1900.07/X	Pg 7	12,5	3,5- 7	15	8	18-22	100/10
1900.09/X	Pg 9	15,5	5 - 8	19	8	22-26	100/10
1900.11/X	Pg11	19	5 -10	22	8	23-28	100/10
1900.13/X	Pg13,5	20,5	7 -12	24	9	24-29	50/10
1900.16/X	Pg16	22,5	10 -14	27	10	26-31	30/10
1900.21/X	Pg21	29	13 -18	33	12	30-35	20/10
1900.29/X	Pg29	37	18 -25	42	12	33-39	20/10
1900.36/X	Pg36	47	20 -32	53	14	42-49	10/5
1900.42/X	Pg42	54	28 -38	60	14	42-50	5/5
1900.48/X	Pg48	60	37 -45	66	15	45-55	5/5