

# COMPRESSION CABLE GLANDS





Brass

2003  
2002  
2001



Material: Metric & Pg threads  
NICKEL PLATED BRASS  
(CuZn 40 Pb 3)  
BSP thread - PLAIN BRASS  
Protection: IP 54  
Sealing ring:  
Metric thread - RUBBER 55sh A  
Pg thread - RUBBER 55 sh A  
BSP thread - PVC 50 sh A

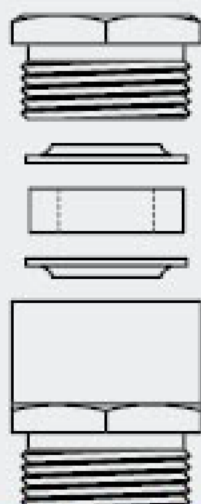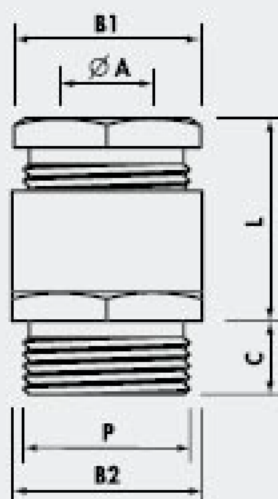

## Metric thread M 1.5 pitch CEI EN 60423 CEI EN 50262

Ref. Nickel Plated Brass	P	Ring Hole Ø (mm)	Ø A min-max (mm)	B1 Spanner Head (mm)	B2 Spanner Body (mm)	C (mm)	L (mm)	Quantity Box/Bag
2003M1221N	M12X1,5	12,5	4- 6	13	14	5	13-16	500/100
2003M1621N	M16X1,5	16,5	8-10	15	17	5	14-17	200/100
2003M2021N	M20X1,5	20,5	10-12	20	22	6	16-19	150/50
2003M2521N	M25X1,5	25,5	17-19	28	30	7	19-23	50/50
2003M3221N	M32X1,5	32,5	26-28	37	39	8	21-25	100/50
2003M4021N	M40X1,5	40,5	33-35	47	50	8	24-30	20/20
2003M5021N	M50X1,5	50,5	39-41	54	57	9	28-34	10/5
2003M6321N	M63X1,5	63,5	43-45	60	66/68	10	30-36	10/5

## Pg thread DIN 40 430 - Dimensions DIN 46 320

Ref. Nickel Plated Brass	P	Ring Hole Ø (mm)	Ø A min-max (mm)	B1 Spanner Head (mm)	B2 Spanner Body (mm)	C (mm)	L (mm)	Quantity Box/Bag
200200721N	Pg 7	12,5	5- 7	13	14	5	13-16	100/100
200200921N	Pg 9	15,5	8-10	15	17	6	14-17	300/100
200201121N	Pg11	19	8-10	18	20	6	14-18	100/50
200201321N	Pg13,5	20,5	10-12	20	22	6,5	16-19	100/50
200201621N	Pg16	22,5	12-14	22	24	6,5	17-20	50/50
200202121N	Pg21	29	17-19	28	30	7	19-23	50/50
200202921N	Pg29	37	26-28	37	40	8	21-25	15/15
200203621N	Pg36	47	33-35	47	50	9	24-30	10/10
200204221N	Pg42	54	39-41	54	57	10	28-34	10/10
200204821N	Pg48	60	43-45	60	64	10	30-36	10/10

## BSP thread ISO 228/1

Ref. Brass	P	Ring Hole Ø (mm)	Ø A min-max (mm)	B1 Spanner Head (mm)	B2 Spanner Body (mm)	C (mm)	L (mm)	Quantity Box/Bag
200101441	G1/4"	13,5	5,5- 7	13	15	6,5	14-17	400/100
207101441	G1/4"	13,5	5,5- 7	13	Ø15	6,5	14-17	400/100
200103841	G3/8"	17	6,5- 8,5	17	19	7,5	15-19	200/100
200101241	G1/2"	21,5	8 -11	21	23	8	17-23	100/100
200105841	G5/8"	23,5	11 -14	23	25	8,5	20-24	100/50
200103441	G3/4"	27	14,5-17,5	27	29	9	20-26	50/50
200110041	G1"	34	18 -22	34	36	10	23-28	25/25
200111841	G1"1/8	38	21 -26	38	40	10,5	23-28	25/25
200111441	G1"1/4	42	28 -32	42	45	11,5	25-31	20/20
200111241	G1"1/2	48	32 -36	48	50	11,5	28-35	20/20
200120041	G2"	60	38 -42	60	64	13,5	31-37	10/10
• 200121221	G2"1/2	76	44 -57	80	80	20	32-37	5/5
• 200130021	G3"	89	67 -69	95	95	20	42-52	5/5

Add to Ref. N for NICKEL PLATED BRASS

• Sealing ring: CLOROPRENE