




for flexible copper cables

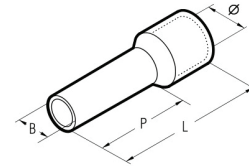

The PKD range of ferrules is manufactured from tin plated electrolytic copper. Designed and developed to reinforce the fine wire strands, when terminating a cable into a connector block. The PKD series of insulated ferrules comply with specification DIN 46 228/4. The operating temperature range is - 4 to + 239 °F (Surge + 266 °F).

HALOGEN FREE



VALSTAR ND#2/PKD

Comprising:
- a selection of end sleeves PKD conductor size 17÷10 AWG
- tool ND#2

VALSTAR ND#2/PKE

Comprising:
- a selection of end sleeves PKE conductor size 17÷10 AWG
- tool ND#2

VALSTAR ND#2/PKC

Comprising:
- a selection of end sleeves PKC conductor size 17÷10 AWG
- tool ND#2

Conductor Size AWG	Ref.	Dimensions in.				Insulation Color	Quantity Box/Bag
		Ø	B	P	L		
22÷20	PKD 506	0.10	0.06	0.24	0.47	○ white	10,000/500
	PKD 508	0.10	0.06	0.31	0.55		10,000/500
	PKD 510	0.10	0.06	0.39	0.63		10,000/500
18	PKD 7506	0.11	0.06	0.24	0.47	○ grey	10,000/500
	PKD 7508	0.11	0.06	0.31	0.55		10,000/500
	PKD 7510	0.11	0.06	0.39	0.63		10,000/500
17	PKD 7512	0.11	0.06	0.47	0.71	● red	10,000/500
	PKD 106	0.12	0.07	0.24	0.47		10,000/500
	PKD 108	0.12	0.07	0.31	0.55		10,000/500
16	PKD 110	0.12	0.07	0.39	0.63	● black	10,000/500
	PKD 112	0.12	0.07	0.47	0.71		10,000/500
	PKD 1508	0.14	0.08	0.31	0.55		5,000/500
14	PKD 1510	0.14	0.08	0.39	0.63	● blue	5,000/500
	PKD 1512	0.14	0.08	0.47	0.71		5,000/500
	PKD 1518	0.14	0.08	0.71	0.94		5,000/500
12	PKD 2508	0.17	0.1	0.31	0.55	● grey	5,000/500
	PKD 2512	0.17	0.1	0.47	0.71		4,000/500
	PKD 2518	0.17	0.1	0.71	0.94		5,000/500
10	PKD 410	0.19	0.13	0.39	0.71	● yellow	3,000/200
	PKD 412	0.19	0.13	0.47	0.79		3,000/200
	PKD 418	0.19	0.13	0.71	1.02		3,000/200
8÷7	PKD 612	0.25	0.16	0.47	0.79	● red	1,500/100
	PKD 618	0.25	0.16	0.71	1.02		2,000/100
	PKD 1012	0.30	0.2	0.47	0.87		1,000/100
6÷5	PKD 1018	0.30	0.2	0.71	1.10	● blue	1,000/100
	PKD 1612	0.35	0.25	0.47	0.94		800/100
	PKD 1618	0.35	0.25	0.71	1.10		1,000/100
4	PKD 25016	0.44	0.31	0.63	1.18	● yellow	500/50
	PKD 25022	0.44	0.31	0.87	1.42		500/50
2	PKD 35016	0.50	0.35	0.63	1.18	● red	400/50
	PKD 35025	0.50	0.35	0.98	1.54		400/50
1/0	PKD 50020	0.59	0.43	0.79	1.42	● blue	200/50
	PKD 50025	0.59	0.43	0.98	1.61		200/50

Wire Ferrule Crimp Tools Available from ASI

PNB-6KE, 2591260
PNB-7KE, 2591268



ND#1, 2590080
ND#2, 2590082
ND#3, 2590084
ND#4, 2590086

