

MAXIbrass® CABLE GLANDS

Nickel Plated Brass


2900



MAXIbrass® extended thread

Pg thread DIN 40 430

Ref. Nickel Plated Brass	P	Fixing Hole Ø (mm)	Ø A min-max (mm)	B Spanner (mm)	E (mm)	C (mm)	L min-max (mm)	Quantity
2901.07N	Pg 7	12.5	3 - 7	16	18	12	16-20	100
2901.09N	Pg 9	15.5	4 - 8	17	19	12	17-23	100
2901.11N	Pg11	19.0	4.5-10	20	23	12	20-25	100
2901.13N	Pg13.5	20.5	5 -12	22	25	12	20-26	50
2901.16N	Pg16	22.5	7 -13	24	27	12	20-27	50
2901.21N	Pg21	29.0	10 -17	30	33	12	24-30	50
2901.29N	Pg29	37.0	17 -25	40	45	15	30-37	25
2901.36N	Pg36	47.0	20 -32	50	55	15	38-48	10
2901.42N	Pg42	54.0	28 -38	57	63	15	39-48	5

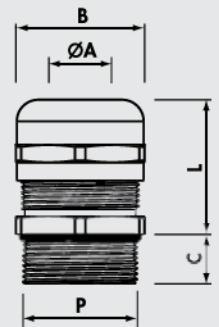

MAXIbrass® extended thread and reduced cable entry

Pg thread DIN 40 430

Ref. Nickel Plated Brass	P	Fixing Hole Ø (mm)	Ø A min-max (mm)	B Spanner (mm)	E (mm)	C (mm)	L min-max (mm)	Quantity
2911.07N	Pg 7	12.5	1 - 5	16	18	12	16-20	100
2911.09N	Pg 9	15.5	2 - 6	17	19	12	17-23	100
2911.11N	Pg11	19.0	2.5- 7	20	23	12	20-25	100
2911.13N	Pg13.5	20.5	4 -10	22	25	12	20-26	50
2911.16N	Pg16	22.5	5 -10	24	27	12	20-27	50
2911.21N	Pg21	29.0	6 -13	30	33	12	24-30	50
2911.29N	Pg29	37.0	11 -20	40	45	15	30-37	25
2911.36N	Pg36	47.0	18 -26	50	55	15	38-48	10
2911.42N	Pg42	54.0	24 -31	57	63	15	39-48	5

