


- 4-Level terminal block
- Top 3 Levels are feed through
- Bottom Level-Ground (PE)
- Gray housing
- Nickel-Plated Copper Metal Bodies
- Fully Enclosed, no end cover required.

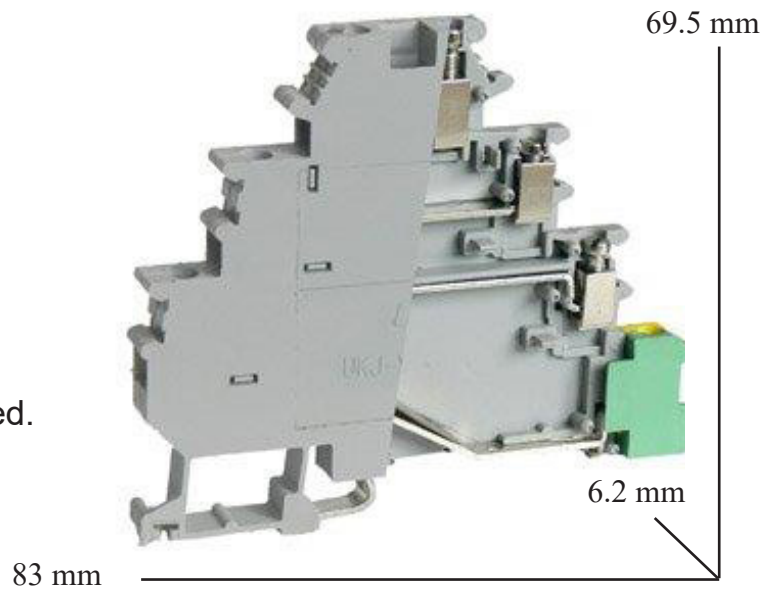

Dimensions

Width/Depth/Height (mm) 6.2 x 83 x 69.5

Technical Parameters

IEC Voltage (V) Rating	400
IEC Current (A) Rating	26
IEC Wire Range (AWG)	24-12
Screw Size	M3
Torque (Nm)	0.6-0.8
Stripping Length (mm)	8

Accessories

ASI013002	UFBI10-6 Screw-In Bridge
-----------	--------------------------