



- Drop-in replacements to major manufacturers
- Wire range 28 to 10 AWG
- Single level, double level, multi-wire, ground and fuse terminal blocks available
- Material of housing: UL94V0 polyamide
- Multiple labeling options

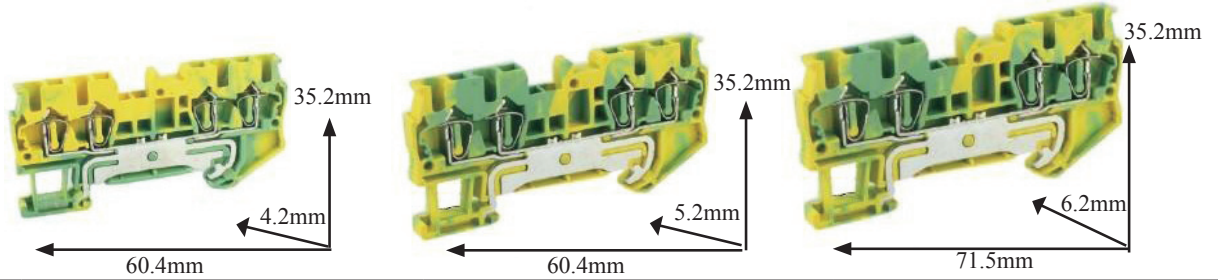

Ordering Info			
Order #	ASI421018	ASI421019	ASI421020
Type	ASIUJ5-1.5/2x2JD	ASIUJ5-2.5/2x2JD	ASIUJ5-4/2x2JD
Description	Ground Terminal Block	Ground Terminal Block	Ground Terminal Block
Pkg Size	50 pcs	50 pcs	50 pcs
Specifications			
Wire Range (AWG)	28-14	28-12	28-10
Voltage Rating (V)			
Current Rating (A)			
Color	Green/Yellow	Green/Yellow	Green/Yellow
Accessories			
	Order #	Order #	Order #
End Cover	ASI422006	ASI422006	ASI422008
Labeling Strip	ASIZB410B, ASI424001	ASIZB510B, ASI424004	ASIZB610B, ASI424007
End Stop	ASIUD1B	ASIUD1B	ASIUD1B
DIN Rail 1-Meter			
7.5 x 35mm slotted	PR005-1M	PR005-1M	PR005-1M
7.5 x 35mm non-slotted	PR003-1M	PR003-1M	PR003-1M
DIN Rail 2-Meter			
7.5 x 35mm slotted	PR005	PR005	PR005
7.5 x 35mm non-slotted	PR003	PR003	PR003

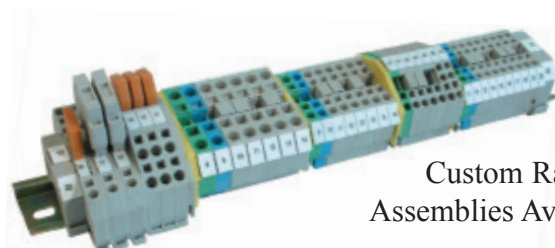

Custom Rail Assemblies Available