


- Drop-in replacements to major manufacturers
- Wire range 28 to 10 AWG
- Single level, double level, multi-wire, ground and fuse terminal blocks available
- Material of housing: UL94V0 polyamide
- Multiple labeling options



Ordering Info			
<b>Order #</b>	ASI421024	ASI421025	ASI421026
<b>Type</b>	ASIUJ5-1.5/2-2JD	ASIUJ5-2.5/2-2JD	ASIUJ5-4/2-2JD
<b>Description</b>	Ground Terminal Block	Ground Terminal Block	Ground Terminal Block
<b>Pkg Size</b>	50 pcs	50 pcs	50 pcs
Specifications			
<b>Wire Range (AWG)</b>	28-14	28-12	28-10
<b>Voltage Rating (V)</b>			
<b>Current Rating (A)</b>			
<b>Color</b>	Green/Yellow	Green/Yellow	Green/Yellow
Accessories			
	<b>Order #</b>	<b>Order #</b>	<b>Order #</b>
<b>End Cover</b>	ASI422010	ASI422010	ASI422036
<b>Labeling Strip</b>	ASIZB410B, ASI424001	ASIZB510B, ASI424004	ASIZB610B, ASI424007
<b>End Stop</b>	ASIUD1B	ASIUD1B	ASIUD1B
<b>DIN Rail 1-Meter</b> 7.5 x 35mm slotted 7.5 x 35mm non-slotted	PR005-1M PR003-1M	PR005-1M PR003-1M	PR005-1M PR003-1M
<b>DIN Rail 2-Meter</b> 7.5 x 35mm slotted 7.5 x 35mm non-slotted	PR005 PR003	PR005 PR003	PR005 PR003

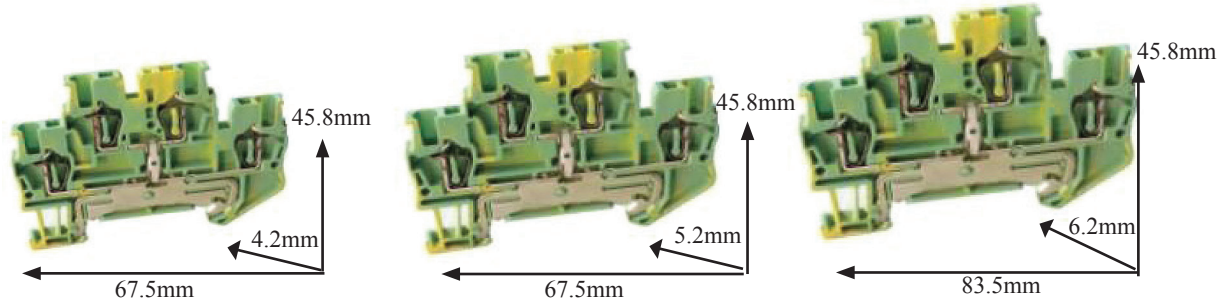