


- Drop-in replacements to major manufacturers
- Models are 28 to 6 AWG, 15 to 115A, 300 to 600V
- Single level, double level, multi-wire, ground and fuse terminal blocks available
- Material of housing: UL94V0 polyamide
- Easy to install push-in jumpers
- Multiple labeling options

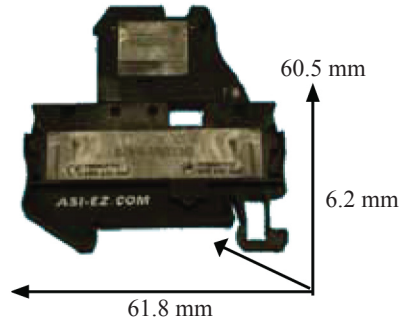

Ordering Info		
<b>Order #</b>	ASI421039	24V Indication: ASI421040 60V Indication: ASI421041 250V Indication: ASI21042
<b>Type</b>	ASIUJ5-4RD(5x20)	24V Indication: ASIUJ5-4RDx24(5x20) 60V Indication: ASIUJ5-4RDx60(5x20) 250V Indication: ASIUJ5-4RDx250(5x20)
<b>Description</b>	Fuse Holder Terminal Block	Fuse Holder Terminal Block
<b>Pkg Size</b>	50 pcs	50 pcs
Specifications		
<b>Wire Range (AWG)</b>	24-10	24-10
<b>Voltage Rating (V)</b>	250	250
<b>Current Rating (A)</b>	6.3	6.3
<b>Color</b>	Black	Black
Accessories		
	<b>Order #</b>	<b>Order #</b>
<b>Partition Plate</b>	ASI422016	ASI422016
<b>Push-In Jumpers</b>		
2-pos	ASI423011	ASI423011
3-pos	ASI423012	ASI423012
4-pos	ASI423013	ASI423013
5-pos	ASI423014	ASI423014
10-pos	ASI423015	ASI423015
<b>Labeling Strip</b>	ASI014002	ASI014002
<b>End Stop</b>	ASIUD1B	ASIUD1B
<b>DIN Rail 1-Meter</b>		
7.5 x 35mm slotted	PR005-1M	PR005-1M
7.5 x 35mm non-slotted	PR003-1M	PR003-1M
<b>DIN Rail 2-Meter</b>		
7.5 x 35mm slotted	PR005	PR005
7.5 x 35mm non-slotted	PR003	PR003