


Spring Clamp DIN Rail Mounted Terminal Blocks

- Drop-in replacements to major manufacturers
- Models are 28 to 6 AWG, 15 to 115A, 300 to 600V
- Single level, double level, multi-wire, ground and fuse terminal blocks available
- Material of housing: UL94V0 polyamide
- Easy to install push-in jumpers
- Multiple labeling options

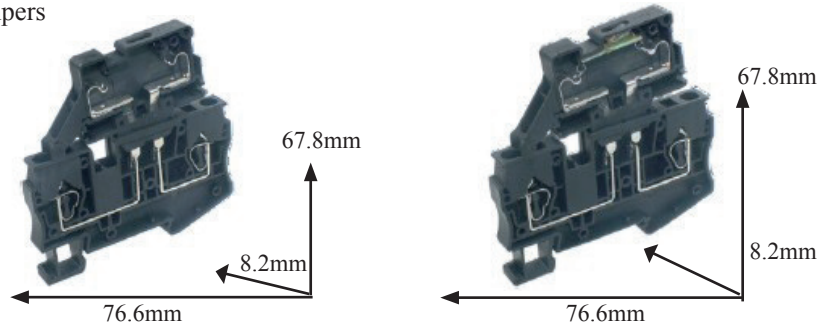

| Ordering Info | | |
|---------------------------|----------------------------|--|
| Order # | ASI421043 | 24V Indication: ASI421044 60V Indication: ASI421085 250V Indication: ASI421045 |
| Type | ASIUJ5-4RD (6.3x32) | 24V Indication: ASIUJ5-4RDx24 (6.3x32) 60V Indication: ASIUJ5-4RDx60 (6.3x32) 250V Indication: ASIUJ5-4RDx250 (6.3x32) |
| Description | Fuse Holder Terminal Block | Fuse Holder Terminal Block |
| Pkg Size | 50 pcs | 50 pcs |
| Specifications | | |
| Wire Range (AWG) | 24-10 | 24-10 |
| Voltage Rating (V) | 500 | 500 |
| Current Rating (A) | 10 | 10 |
| Color | Black | Black |

| Accessories | | |
|-------------------------|-----------|-----------|
| | Order # | Order # |
| Push-In Jumpers | | |
| 2-pos | ASI423016 | ASI423016 |
| 3-pos | ASI423017 | ASI423017 |
| 4-pos | ASI423018 | ASI423018 |
| 5-pos | ASI423019 | ASI423019 |
| 10-pos | ASI423020 | ASI423020 |
| Labeling Strip | ASI014003 | ASI014003 |
| End Stop | ASIUD1B | ASIUD1B |
| DIN Rail 1-Meter | | |
| 7.5 x 35mm slotted | PR005-1M | PR005-1M |
| 7.5 x 35mm non-slotted | PR003-1M | PR003-1M |
| DIN Rail 2-Meter | | |
| 7.5 x 35mm slotted | PR005 | PR005 |
| 7.5 x 35mm non-slotted | PR003 | PR003 |