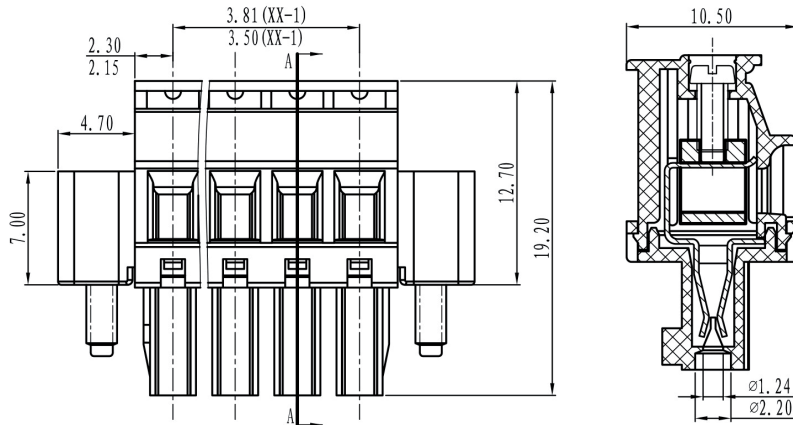

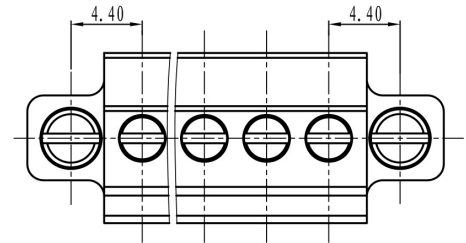


PCB Terminal Blocks Connector, Right/Bottom Wire Entry with Screw Lock ASIWJ15EDGKBM-3.81



| Certification | |
|---|--|
|  | |
| Material | |
| Lock Screw | M2.5 Steel, Tin Plated |
| Screw | M2.0 Steel, Tin Plated |
| Pin/Plate | Phosphor Bronze, Nickel Plated |
| Cage | Brass, Nickel Plated |
| Applicator | Steel, Tin Plated |
| Housing | PA66, UL 94V-0, Green |
| Electrical | |
| Standard | UL 1059/CSA C22.2 No. 158 |
| Rated Voltage | 300 V |
| Rated Current | 8 A |
| Wire Range | 28-16 AWG |
| Contact Resistance | 20mΩ |
| Insulation Resistance | 500MΩ/500 Vdc |
| Withstand Voltage | 2000 Vac/1 Min |
| Mechanical | |
| Temperature Range | -40°C...+105°C |
| Torque | 0.2N-m (1.8lb-in) |
| Strip Length | 6-7 mm (0.24-0.28") |
| Size | |
| Pitch | 3.81 mm (.150") |
| Poles | 2P-16P. Additional sizes available on request. |



| Item | No. of Poles | Length (mm) |
|------------------------|--------------|-------------|
| ASIWJ15EDGKBM-3.81-2P | 2 | 17.81 |
| ASIWJ15EDGKBM-3.81-3P | 3 | 21.62 |
| ASIWJ15EDGKBM-3.81-4P | 4 | 25.43 |
| ASIWJ15EDGKBM-3.81-5P | 5 | 29.24 |
| ASIWJ15EDGKBM-3.81-6P | 6 | 33.05 |
| ASIWJ15EDGKBM-3.81-7P | 7 | 36.86 |
| ASIWJ15EDGKBM-3.81-8P | 8 | 40.67 |
| ASIWJ15EDGKBM-3.81-9P | 9 | 44.48 |
| ASIWJ15EDGKBM-3.81-10P | 10 | 48.29 |
| ASIWJ15EDGKBM-3.81-11P | 11 | 52.1 |
| ASIWJ15EDGKBM-3.81-12P | 12 | 55.91 |
| ASIWJ15EDGKBM-3.81-13P | 13 | 59.72 |
| ASIWJ15EDGKBM-3.81-14P | 14 | 63.53 |
| ASIWJ15EDGKBM-3.81-15P | 15 | 67.34 |
| ASIWJ15EDGKBM-3.81-16P | 16 | 71.15 |