
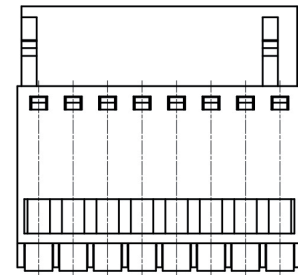
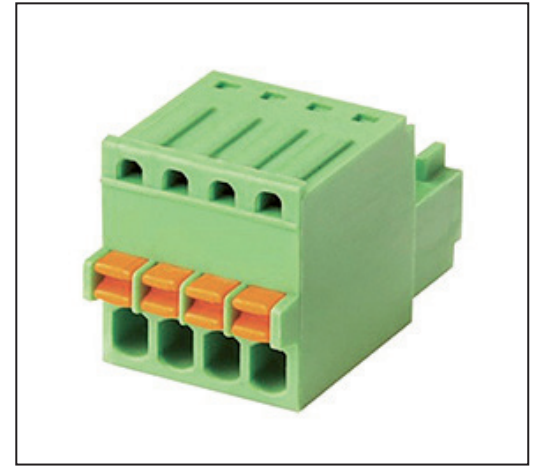
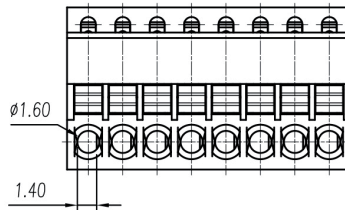
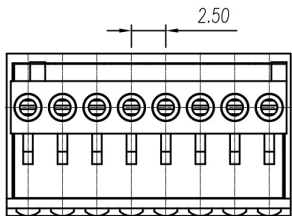
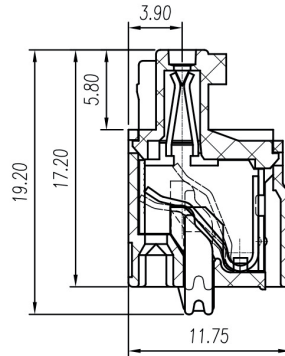


PCB Terminal Blocks Connector, Top Wire Entry with Spring Clamp Termination ASIWJ15EDGKD-2.5

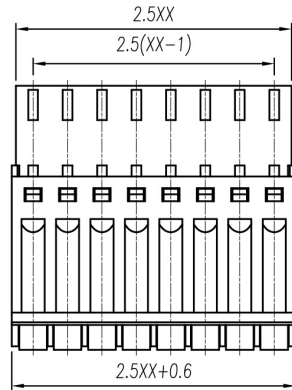

Certification	
Material	
Pin/Plate	Phosphor Bronze, Nickel Plated
Spring	Stainless Steel
Housing	PA66, UL 94V-0, Green
Electrical	
Standard	UL 1059/CSA C22.2 No. 158
Rated Voltage	150 V
Rated Current	5 A
Wire Range	26-20 AWG
Contact Resistance	20mΩ
Insulation Resistance	500MΩ/500 Vdc
Withstand Voltage	1500 Vac/1 Min
Mechanical	
Temperature Range	-40°C...+105°C
Strip Length	7-8 mm (0.28-0.31")
Size	
Pitch	2.5 mm (.098")
Poles	2P-12P. Additional sizes available on request.

Item	No. of Poles	Length (mm)
ASIWJ15EDGKD-2.5-2P	2	5.6
ASIWJ15EDGKD-2.5-3P	3	8.1
ASIWJ15EDGKD-2.5-4P	4	10.6
ASIWJ15EDGKD-2.5-5P	5	13.1
ASIWJ15EDGKD-2.5-6P	6	15.6
ASIWJ15EDGKD-2.5-7P	7	18.1
ASIWJ15EDGKD-2.5-8P	8	20.6
ASIWJ15EDGKD-2.5-9P	9	23.1
ASIWJ15EDGKD-2.5-10P	10	25.6
ASIWJ15EDGKD-2.5-11P	11	28.1
ASIWJ15EDGKD-2.5-12P	12	30.6