
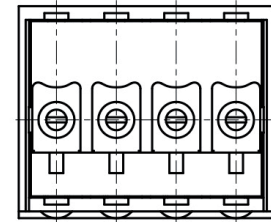



PCB Terminal Blocks Connector, Top Wire Entry with Spring Clamp Termination ASIWJ15EDGKD-3.5

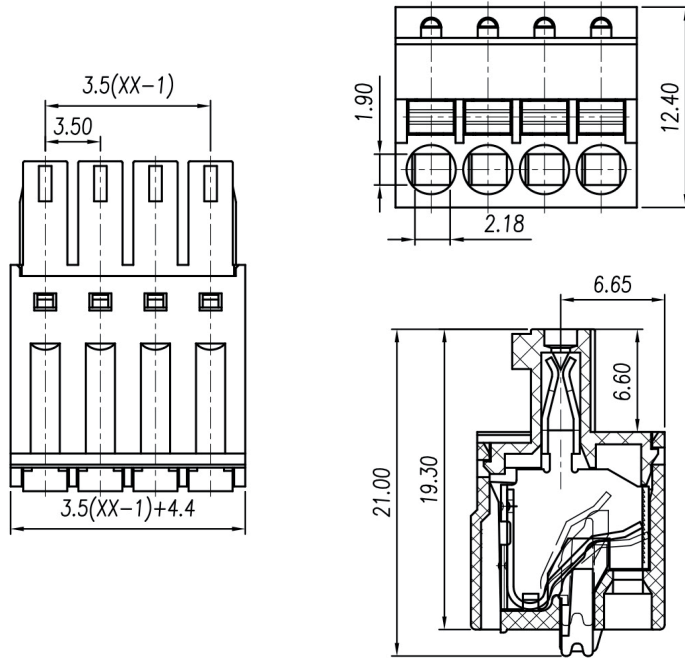

Certification	
	
Material	
Pin/Plate	Phosphor Bronze, Nickel Plated
Spring	Stainless Steel
Housing	PA66, UL 94V-0, Green
Electrical	
Standard	UL 1059/CSA C22.2 No. 158
Rated Voltage	300 V
Rated Current	8 A
Wire Range	28-16 AWG
Contact Resistance	20mΩ
Insulation Resistance	500MΩ/500 Vdc
Withstand Voltage	2000 Vac/1 Min
Mechanical	
Temperature Range	-40°C...+105°C
Strip Length	6-7 mm (0.24-0.28")
Size	
Pitch	3.5 mm (.138")
Poles	2P-16P. Additional sizes available on request.

Item	No. of Poles	Length (mm)
ASIWJ15EDGKD-3.5-2P	2	7.9
ASIWJ15EDGKD-3.5-3P	3	11.4
ASIWJ15EDGKD-3.5-4P	4	14.9
ASIWJ15EDGKD-3.5-5P	5	18.4
ASIWJ15EDGKD-3.5-6P	6	21.9
ASIWJ15EDGKD-3.5-7P	7	25.4
ASIWJ15EDGKD-3.5-8P	8	28.9
ASIWJ15EDGKD-3.5-9P	9	32.4
ASIWJ15EDGKD-3.5-10P	10	35.9
ASIWJ15EDGKD-3.5-11P	11	39.4
ASIWJ15EDGKD-3.5-12P	12	42.9
ASIWJ15EDGKD-3.5-13P	13	46.4
ASIWJ15EDGKD-3.5-14P	14	49.9
ASIWJ15EDGKD-3.5-15P	15	53.4
ASIWJ15EDGKD-3.5-16P	16	56.9