
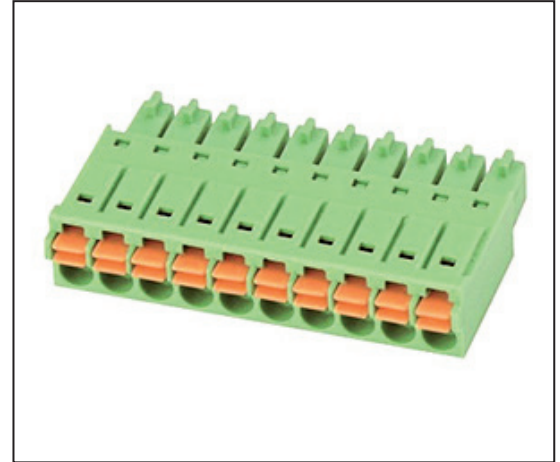



# PCB Terminal Blocks

## Low Profile Narrow Connector, Top Wire Entry with Spring Clamp Termination

### ASIWJ15EDGKN-3.5

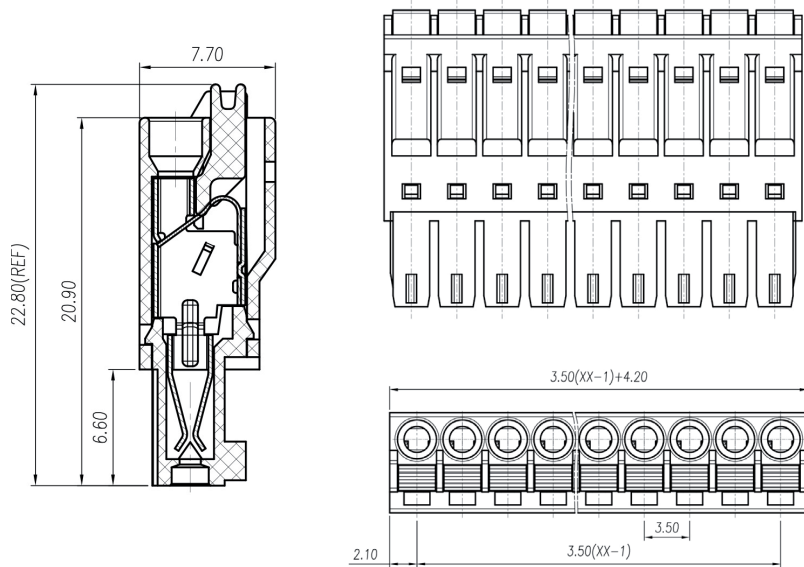

Certification	
	
Material	
Pin/Plate	Phosphor Bronze, Nickel Plated
Spring	Stainless Steel
Housing	PA66, UL 94V-0, Green
Electrical	
Standard	UL 1059/CSA C22.2 No. 158
Rated Voltage	300 V
Rated Current	8 A
Wire Range	24-16 AWG
Contact Resistance	20mΩ
Insulation Resistance	500MΩ/500 Vdc
Withstand Voltage	2000 Vac/1 Min
Mechanical	
Temperature Range	-40°C...+105°C
Strip Length	9-10 mm (0.35-0.39")
Size	
Pitch	3.5 mm (.138")
Poles	2P-16P. Additional sizes available on request.

Item	No. of Poles	Length (mm)
ASIWJ15EDGKN-3.5-2P	2	7.7
ASIWJ15EDGKN-3.5-3P	3	11.2
ASIWJ15EDGKN-3.5-4P	4	14.7
ASIWJ15EDGKN-3.5-5P	5	18.2
ASIWJ15EDGKN-3.5-6P	6	21.7
ASIWJ15EDGKN-3.5-7P	7	25.2
ASIWJ15EDGKN-3.5-8P	8	28.7
ASIWJ15EDGKN-3.5-9P	9	32.2
ASIWJ15EDGKN-3.5-10P	10	35.7
ASIWJ15EDGKN-3.5-11P	11	39.2
ASIWJ15EDGKN-3.5-12P	12	42.7
ASIWJ15EDGKN-3.5-13P	13	46.2
ASIWJ15EDGKN-3.5-14P	14	49.7
ASIWJ15EDGKN-3.5-15P	15	53.2
ASIWJ15EDGKN-3.5-16P	16	56.7