


PCB Terminal Blocks Double Level Vertical Offset Header ASIWJ15EDGVT-3.81

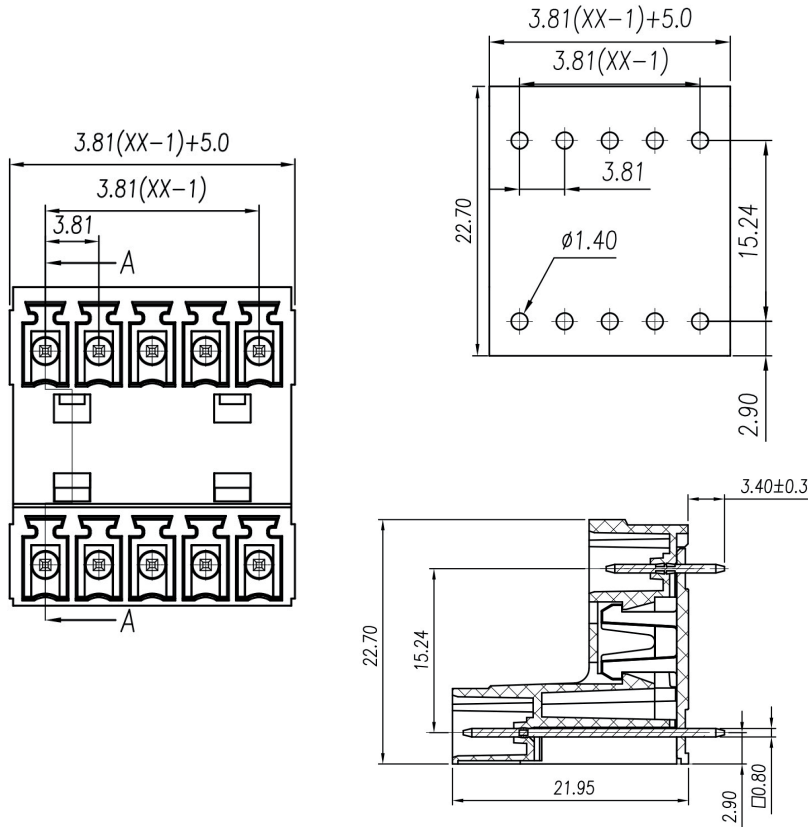

Certification	
	
Material	
Lock Nut	M2.5, Brass Plated
Pin/Plate	Brass, Tin Plated
Housing	PA66, UL 94V-0, Green
Electrical	
Standard	UL 1059/CSA C22.2 No. 158
Rated Voltage	300 V
Rated Current	8 A
Contact Resistance	20mΩ
Insulation Resistance	500MΩ/500 Vdc
Withstand Voltage	2000 Vac/1 Min
Mechanical	
Temperature Range	-40°C...+105°C
Size	
Pitch	3.81 mm (.150")
Poles	2P-16P. Additional sizes available on request.

Item	No. of Poles	Length (mm)
ASIWJ15EDGVT-3.81-2P	2	8.81
ASIWJ15EDGVT-3.81-3P	3	12.62
ASIWJ15EDGVT-3.81-4P	4	16.43
ASIWJ15EDGVT-3.81-5P	5	20.24
ASIWJ15EDGVT-3.81-6P	6	24.05
ASIWJ15EDGVT-3.81-7P	7	27.86
ASIWJ15EDGVT-3.81-8P	8	31.67
ASIWJ15EDGVT-3.81-9P	9	35.48
ASIWJ15EDGVT-3.81-10P	10	39.29
ASIWJ15EDGVT-3.81-11P	11	43.1
ASIWJ15EDGVT-3.81-12P	12	46.91
ASIWJ15EDGVT-3.81-13P	13	50.72
ASIWJ15EDGVT-3.81-14P	14	54.53
ASIWJ15EDGVT-3.81-15P	15	58.34
ASIWJ15EDGVT-3.81-16P	16	62.15