
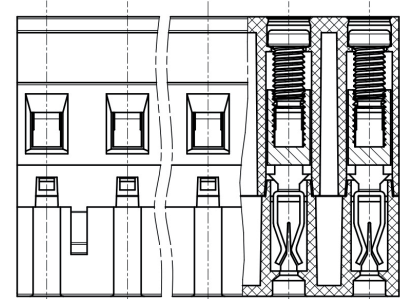


| Certification | |
|---|--|
|  | |
| Material | |
| Screw | M3.0 Steel, Tin Plated |
| Pin/Plate | Phosphor Bronze, Nickel Plated |
| Cage | Brass, Nickel Plated |
| Housing | PA66, UL 94V-0, Green |
| Electrical | |
| Standard | UL 1059/CSA C22.2 No. 158 |
| Rated Voltage | 300 V |
| Rated Current | 15 A |
| Wire Range | 28-14 AWG |
| Contact Resistance | 20mΩ |
| Insulation Resistance | 500MΩ/500 Vdc |
| Withstand Voltage | 2000 Vac/1 Min |
| Mechanical | |
| Temperature Range | -40°C...+105°C |
| Torque | 0.5N-m (4.4lb-in) |
| Strip Length | 7-8 mm (0.28-0.31") |
| Size | |
| Pitch | 7.5 mm (.295") |
| Poles | 2P-12P. Additional sizes available on request. |



| Item | No. of Poles | Length (mm) |
|---------------------|--------------|-------------|
| ASIWJ2EDGKA-7.5-2P | 2 | 13 |
| ASIWJ2EDGKA-7.5-3P | 3 | 20.5 |
| ASIWJ2EDGKA-7.5-4P | 4 | 28 |
| ASIWJ2EDGKA-7.5-5P | 5 | 35.5 |
| ASIWJ2EDGKA-7.5-6P | 6 | 43 |
| ASIWJ2EDGKA-7.5-7P | 7 | 50.5 |
| ASIWJ2EDGKA-7.5-8P | 8 | 58 |
| ASIWJ2EDGKA-7.5-9P | 9 | 65.5 |
| ASIWJ2EDGKA-7.5-10P | 10 | 73 |
| ASIWJ2EDGKA-7.5-11P | 11 | 80.5 |
| ASIWJ2EDGKA-7.5-12P | 12 | 88 |