
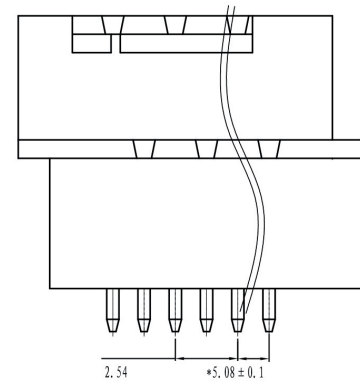


PCB Terminal Blocks Double Level Vertical Offset Header with Screw Lock ASIWJ2EDGVTM-5.08

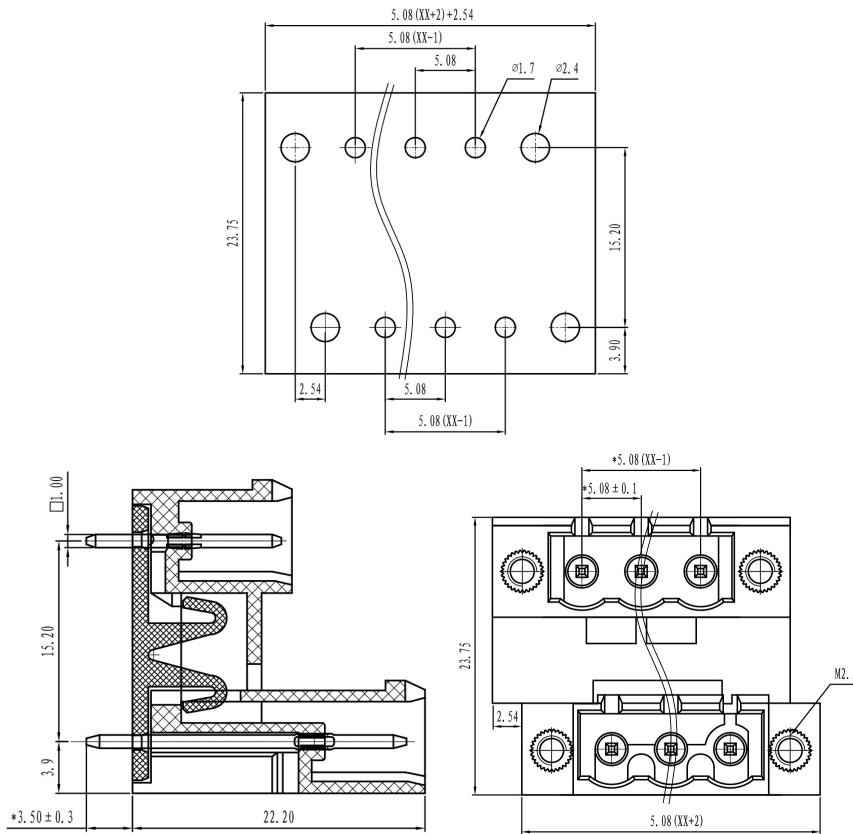

Certification	
Material	
Locking Nut	M2.5, Brass Plated
Pin/Plate	Brass, Tin Plated
Housing	PA66, UL 94V-0, Green
Electrical	
Standard	UL 1059/CSA C22.2 No. 158
Rated Voltage	300 V
Rated Current	15 A
Contact Resistance	20mΩ
Insulation Resistance	500MΩ/500 Vdc
Withstand Voltage	2000 Vac/1 Min
Mechanical	
Temperature Range	-40°C...+105°C
Size	
Pitch	5.08 mm (.200")
Poles	2P-16P. Additional sizes available on request.

Item	No. of Poles	Length (mm)
ASIWJ2EDGVTM-5.08-2P	2	22.86
ASIWJ2EDGVTM-5.08-3P	3	27.94
ASIWJ2EDGVTM-5.08-4P	4	33.02
ASIWJ2EDGVTM-5.08-5P	5	38.1
ASIWJ2EDGVTM-5.08-6P	6	43.18
ASIWJ2EDGVTM-5.08-7P	7	48.26
ASIWJ2EDGVTM-5.08-8P	8	53.34
ASIWJ2EDGVTM-5.08-9P	9	58.42
ASIWJ2EDGVTM-5.08-10P	10	63.5
ASIWJ2EDGVTM-5.08-11P	11	68.58
ASIWJ2EDGVTM-5.08-12P	12	73.66
ASIWJ2EDGVTM-5.08-13P	13	78.74
ASIWJ2EDGVTM-5.08-14P	14	83.82
ASIWJ2EDGVTM-5.08-15P	15	88.9
ASIWJ2EDGVTM-5.08-16P	16	93.98