
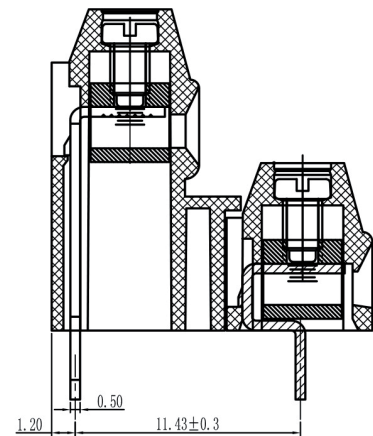



PCB Terminal Blocks, Fixed Horizontal Wire Entry, Double Level, Offset Right ASIWJEK350A-3.5

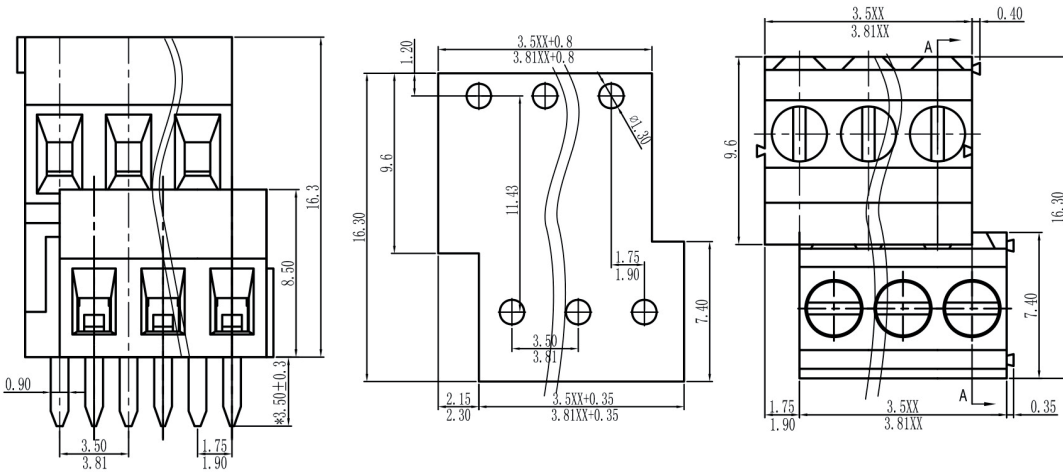

Certification	
	
Material	
Screw	M2.0, Steel Zinc Plated
Clamp	Brass, Nickel Plated
Pin/Plate	Brass, Tin Plated
Housing	PA66, UL 94V-0, Green
Electrical	
Standard	UL 1059/CSA C22.2 No. 158
Rated Voltage	300 V
Rated Current	10 A
Wire Range	30-16 AWG
Contact Resistance	20mΩ
Insulation Resistance	500MΩ/500 Vdc
Withstand Voltage	2000 Vac/1 Min
Mechanical	
Temperature Range	-40°C...+105°C
Torque	0.2N-m (1.8lb-in)
Strip Length	5-6 mm (0.197-0.24")
Size	
Pitch	3.5 mm (.138")
Poles	2P-16P. Additional sizes available on request.

Item	No. of Poles	Length (mm)
ASIWJEK350A-3.5-2P	2	8.75
ASIWJEK350A-3.5-3P	3	12.25
ASIWJEK350A-3.5-4P	4	15.75
ASIWJEK350A-3.5-5P	5	19.25
ASIWJEK350A-3.5-6P	6	22.75
ASIWJEK350A-3.5-7P	7	26.25
ASIWJEK350A-3.5-8P	8	29.75
ASIWJEK350A-3.5-9P	9	33.25
ASIWJEK350A-3.5-10P	10	36.75
ASIWJEK350A-3.5-11P	11	40.25
ASIWJEK350A-3.5-12P	12	43.75
ASIWJEK350A-3.5-13P	13	47.25
ASIWJEK350A-3.5-14P	14	50.75
ASIWJEK350A-3.5-15P	15	54.25
ASIWJEK350A-3.5-16P	16	57.75