
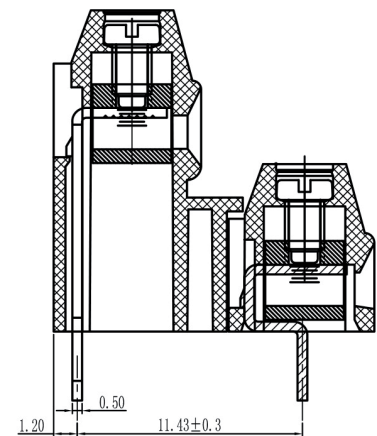



# PCB Terminal Blocks, Fixed Horizontal Wire Entry, Double Level, Offset Right ASIWJEK381A-3.81

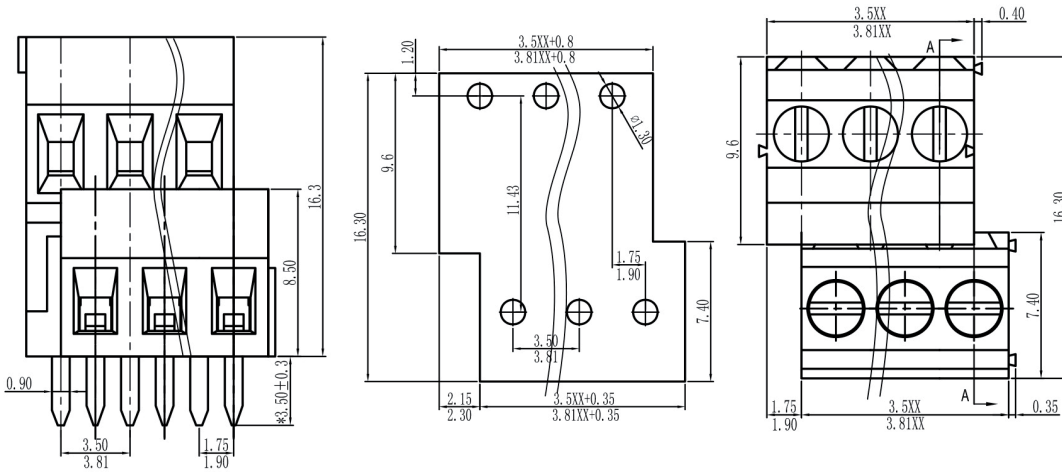

Certification	
	
Material	
Screw	M2.0, Steel Zinc Plated
Clamp	Brass, Nickel Plated
Pin/Plate	Brass, Tin Plated
Housing	PA66, UL 94V-0, Green
Electrical	
Standard	UL 1059/CSA C22.2 No. 158
Rated Voltage	300 V
Rated Current	10 A
Wire Range	30-16 AWG
Contact Resistance	20mΩ
Insulation Resistance	500MΩ/500 Vdc
Withstand Voltage	2000 Vac/1 Min
Mechanical	
Temperature Range	-40°C...+105°C
Torque	0.2N-m (1.8lb-in)
Strip Length	5-6 mm (0.197-0.24")
Size	
Pitch	3.81 mm (.150")
Poles	2P-16P. Additional sizes available on request.

Item	No. of Poles	Length (mm)
ASIWJEK381A-3.81-2P	2	9.52
ASIWJEK381A-3.81-3P	3	13.33
ASIWJEK381A-3.81-4P	4	17.14
ASIWJEK381A-3.81-5P	5	20.95
ASIWJEK381A-3.81-6P	6	24.76
ASIWJEK381A-3.81-7P	7	28.57
ASIWJEK381A-3.81-8P	8	32.38
ASIWJEK381A-3.81-9P	9	36.19
ASIWJEK381A-3.81-10P	10	40.0
ASIWJEK381A-3.81-11P	11	43.81
ASIWJEK381A-3.81-12P	12	47.62