

Low-Cost PCB Terminal Block Header


The CHM pin printed circuit board pin header is used with the CHF low cost pluggable terminal block. It is available in 24 positions and can be cut to fit any number of circuits depending on the application. The pin header is rated for 12 amps at 300 volts.

SPECIFICATIONS

Housing Material: PA68 Polyimide, Flammable UL94V0
 Housing Color: Black
 Screw: Zinc Plated Steel
 Clamp: Nickel Plated Brass
 Pin: Tin Plated Brass
 P.C.B. mounting hole: 1.5mm
 Nominal current: 12 A
 Voltage: 300 V
 Temperature Range: -30° C to 120° C



CHM 5/24

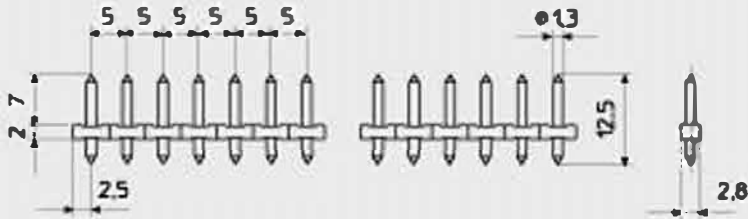

Catalog #	No. of Positions	Length (mm)
CHM5-24	24	120