


Low-Cost, Modular Fixed PCB Terminal Blocks

The CII is a family of miniature printed circuit board terminal blocks. The housings of the CII family of terminal blocks are interlocking. The 2 and 3 position terminal blocks can be joined together to come up with any combination of circuits. The CII is rated at 14 amps, 300 volts, and will handle a wire range of 14-30 AWG. The standard color of the CII family is green, however other colors are available upon request. The UL recognized CII terminal blocks are ideal for industrial applications.

SPECIFICATIONS

Housing Material:	PA68 Polyamide, Flammable UL94V0
Housing Color:	Green
Screw:	Zinc Plated Steel
Clamp:	Nickel Plated Brass
Pin:	Tin Plated Brass
Testing torque:	4.4 in/lb
Wire range:	14-30 AWG
P.C.B. mounting hole:	1.3mm
Nominal current:	14 A
Voltage:	300 V
Temperature Range:	-30° C to 85° C

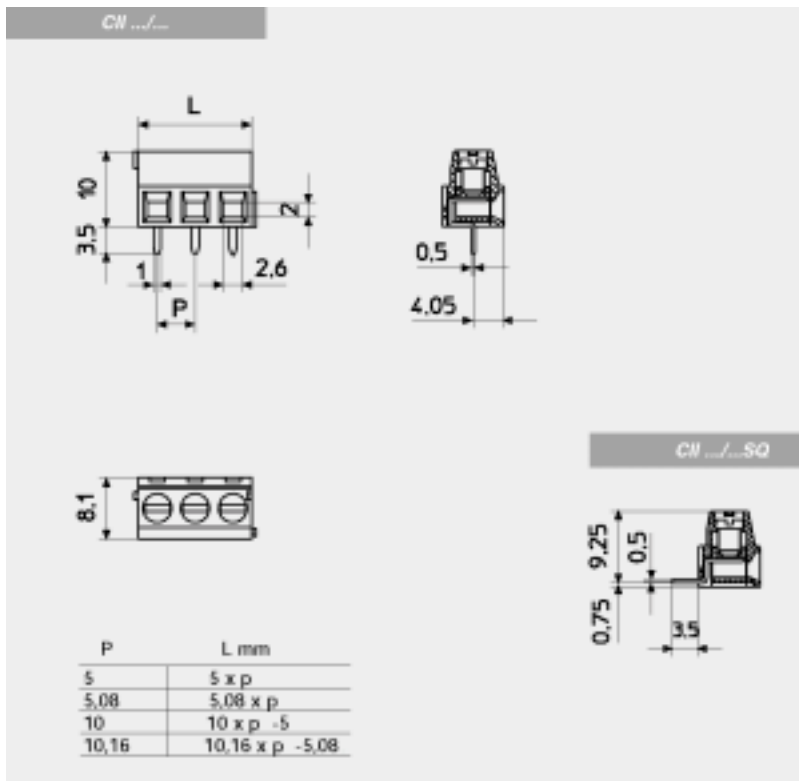

Catalog #	No. of Positions	Length (mm)
CII5.08-2VE	2	10.16
CII5.08-3VE	3	15.24