


# Modular Fixed PCB Terminal Blocks

The CLL family of modular printed circuit board terminal blocks are available in several different pin spacings. The interlocking 2 and 3 position housings reduce inventory requirements since they can be joined together to make up any number of circuits. The CLL is rated at 14 amps, 300 volts and will handle a wire range of 12 to 30 A WG. The CLL is offered in a wide variety of pin spacings and is also available in a right angle pin version. The standard color is green, however other colors are available upon request.



## SPECIFICATIONS

Housing Material:	PA68 Polyamide, Flammable UL94VO
Housing Color:	Green
Screw:	Zinc Plated Steel
Clamp:	Nickel Plated Brass
Pin:	Tin Plated Brass
Testing torque:	4.4 in/lb.
Wire range:	12-30 AWG
P.C.B. mounting hole:	1.3mm
Nominal current:	14 A
Voltage:	300 V
Temperature Range:	-30° C to 85° C

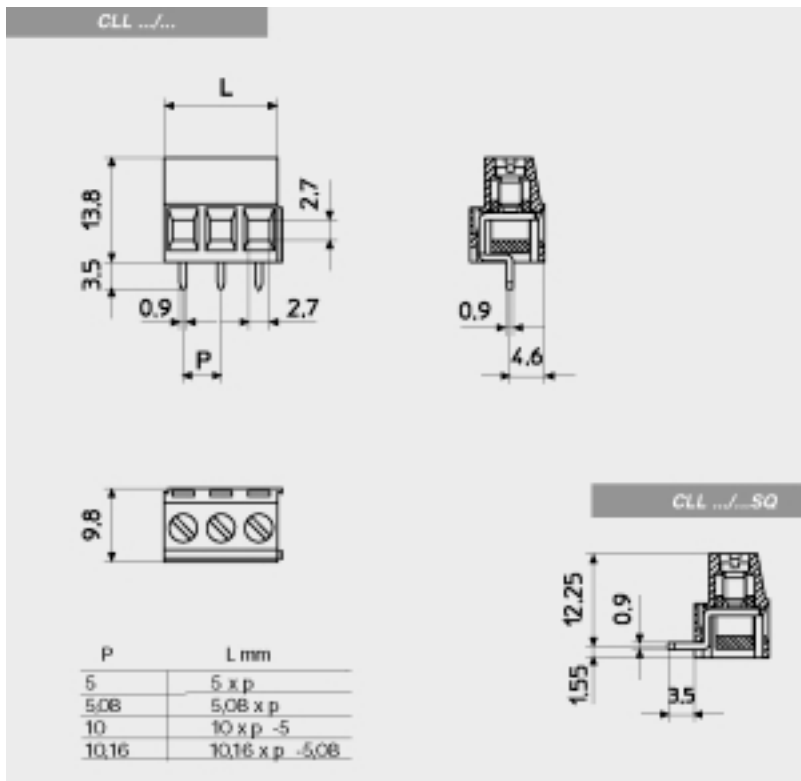

Catalog #	No. of Positions	Length (mm)
CLL5.08-2VE	2	10.16
CLL5.08-3VE	3	15.24