


Angled Wire Entry PCB Terminal Blocks

The COB modular printed circuit board terminal block allows for 45 degree wire access to the printed circuit board. The 2 and 3 position terminal block can be joined together to form any number of circuits and there is a wide range of pin spacing. The UL rating of the COB terminal blocks is 16 amps, 300 volts and will handle a wire range of 12 to 24 AWG. The moving clamp design insures maximum wiring reliability. The standard color is gray and other colors are available upon request.

SPECIFICATIONS

Housing Material:	PA68 Polyimide, Flammable UL94V0
Housing Color:	Gray
Screw:	Zinc Plated Steel
Clamp:	Nickel Plated Brass
Pin:	Tin Plated Brass
Testing torque:	3.5 in/lb
Wire range:	12-24 AWG
P.C.B. mounting hole:	1.3mm
Nominal current:	16 A
Voltage:	300 V
Temperature Range:	-30° C to 85° C

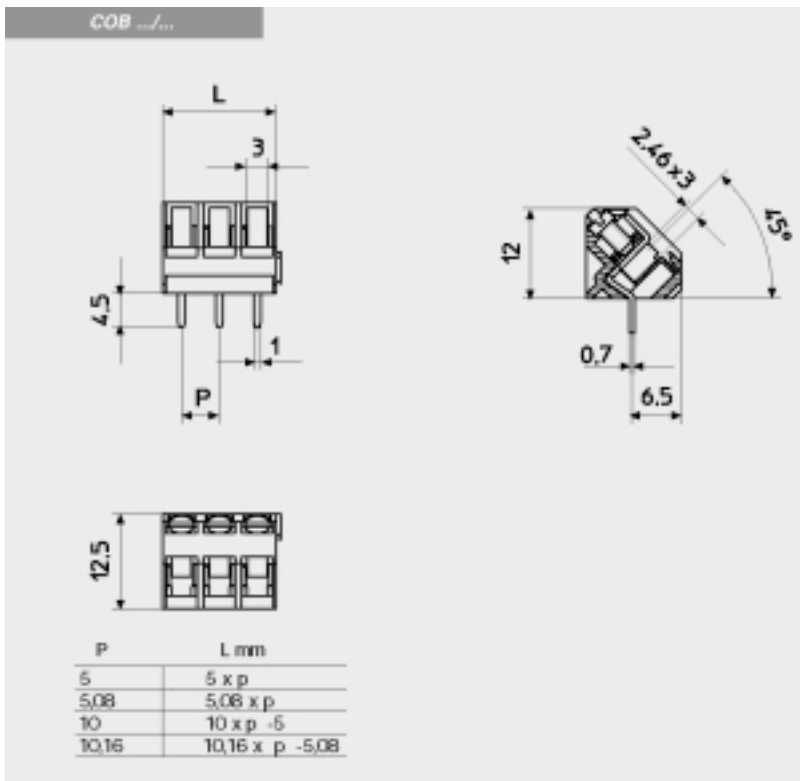

Catalog #	No. of Positions	Length (mm)
COB5-2	2	10
COB5-3	3	15