



Control Loops and current transformer circuits typically require an easy means to quickly and safely open the circuit for testing. The ASIMTK style of terminal block relies on a knife disconnect, which is color-coded orange to open up the circuit and insert for testing such as in process control systems. The ASIURTK series uses different types of jumpers in conjunction with a sliding link to open up and short out at the same time circuits such as CT's for safe testing. The sliding link is operated with the use of a locking screw which insures a reliable operation.




Terminal Width 6.2mm
ASIUK5MTKPP

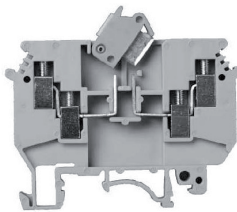

Terminal Width 6.2mm
ASIUDK4MTKPP

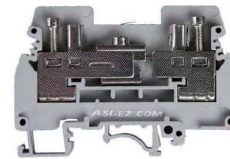

Terminal Width 8.2mm
ASIURTKS

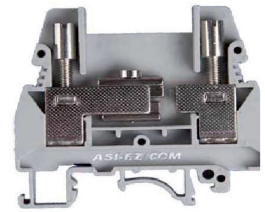

Terminal Width 8.2mm
ASIURTKSBEN

Specifications									
Wire range, AWG	22-12		30-10		16-8		16-8		
Current Rating	15		15		45		50		
Voltage Rating	600		600		600		300		
Dimensions (L x H) mm	63.5 x 58		63.5 x 47		72.8 x 51.5		61 x 58.5		
Ordering Information		Order #	Pcs/ PkG	Order #	Pcs/ PkG	Order #	Pcs/ PkG		
Terminal Block		ASIUK5MTKPP	50	ASIUDK4MTKPP	50	ASIURTKS	50	ASIURTKSBEN	50
Accessories									
End cover				ASIDUDK4	25	ASIDURTK	25	ASIDURTKSBEN	25
Circuit Bridges									
Internal	10 position					ASIFB10RTKS	10		
Switch Bar	10 position					ASIASB2RTKS	10		
Sliding Switch bar	2 position					ASISB203	10		
External									
	2 position	ASIEB 26	25	ASIEB26	25	ASIEB28	25	ASIEB28	25
	3 position	ASIEB36	25	ASIEB36	25	ASIEB38	25	ASIEB38	25
	10 position	ASIEB106	10	ASIEB106	10	ASIEB108	10	ASIEB108	10
TB Markers									
Blank		ASIZB610B	10	ASIZB610B	10	ASIZB810B	10	ASIZB810B	10
Pre-printed 1-10 vert		ASIZB61010V	10	ASIZB61010V	10	ASIZB81010V	10	ASIZB81010V	10
Pre-printed 1-10 horz		ASIZ61010H	10	ASIZ61010H	10	ASIZB81010H	10	ASIZB81010H	10
Custom		ASIZB6C.....	...	ASIZB6C.....	...	ASIZB8C.....	...	ASIZB8C.....	...
End Stop (snap-on) Black		ASIUD1B	25	ASIUD1B	25			ASIUD1B	25
DIN Rail (2 meters)									
7.5 x 35mm slotted		PR005	1	PR005	1	PR005	1	PR005	1
7.5 x 35mm non-slotted		PR003	1	PR003	1	PR003	1	PR003	1
15 x 35mm slotted		PR006	1	PR006	1	PR006	1	PR006	1
15 x 35mm non-slotted		PR007	1	PR007	1	PR007	1	PR007	1



Normal Operation



Current (A)
Value Measuring



Current Transformer
Short Circuit