

MRT18

Interlocking modules - Modulo componibile
Elements modulaires - Zusammensteckbare Blöcke

Poles - Poli - Pôles - Polzahl

 
2/3 (5,08)
1/2 (10,16)



5,08 - 10,16

320 - 630

20



6

0,5

5

110

PA - UL 94 V0

M3





0,6 x 3,5

V	A	mm /AWG
450 (5,08)	750 (10,16)	20
450 (5,08)	750 (10,16)	20
300 (5,08 and 10,16)	20	30 ÷ 12

min 2 - max...

VE / on demand GR GR1 NE AR BL RO GI

D/A1

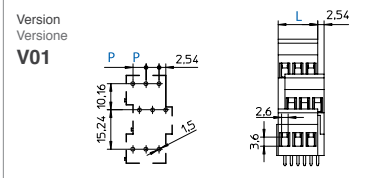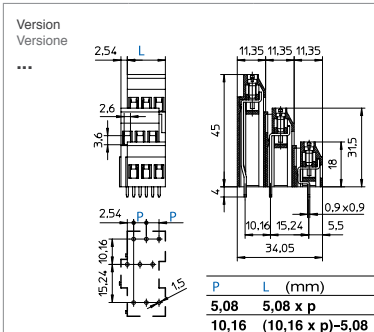

MRT18..V04

Interlocking modules - Modulo componibile
Elements modulaires - Zusammensteckbare Blöcke

Poles - Poli - Pôles - Polzahl

 
2/3 (5,08)
1/2 (10,16)



5,08 - 10,16

320 - 630

20



6

0,5

5

110

PA - UL 94 V0

M3





0,6 x 3,5

V	A	mm /AWG
450 (5,08)	750 (10,16)	20
450 (5,08)	750 (10,16)	20
300 (5,08 and 10,16)	20	30 ÷ 12

min 2 - max...

VE / on demand GR GR1 NE AR BL RO GI

D/A1

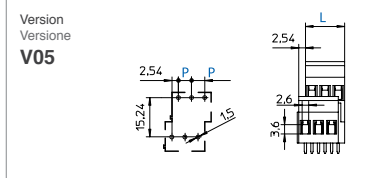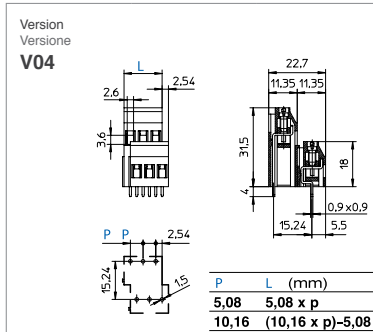

MRT18..V02

Interlocking modules - Modulo componibile
Elements modulaires - Zusammensteckbare Blöcke

Poles - Poli - Pôles - Polzahl

 
2/3 (5,08)
1/2 (10,16)



5,08 - 10,16

320 - 630

20



6

0,5

5

110

PA - UL 94 V0

M3



0,6 x 3,5

V	A	mm /AWG
450 (5,08)	750 (10,16)	20
450 (5,08)	750 (10,16)	20
300 (5,08 and 10,16)	20	30 ÷ 12

min 2 - max...

VE / on demand GR GR1 NE AR BL RO GI

D/A1

