

MRT22

Blocco unico / **Single block**
Monobloc / **Einzelblock**

Poli / **Poles** / **2/20**
Pôles / **Polzahl**



3,5	3,81
200	
10	

0,2 + 1,0	0,2 + 1,0	0,2 + 1,0
30 + 16	30 + 16	30 + 16
5		
0,3	2	
110		
PA - UL 94 V0		
M2		
0,5 x 3		

V	A	mm ² /AWG
300	8	30 + 16

min 2 - max 20		
VE		
80		

Versione / **Version**
Version / **Version**

... **VO1** ...

P	L (mm)	X
3,5	3,5 x p	1,75
3,81	(3,81 x p)+0,79	2,3

MRT22..VO1

Blocco unico / **Single block**
Monobloc / **Einzelblock**

Poli / **Poles** / **2/20**
Pôles / **Polzahl**



3,5	3,81
200	
10	

0,2 + 1	0,2 + 1	0,2 + 1
30 + 16	30 + 16	30 + 16
5		
0,3	2	
110		
PA - UL 94 V0		
M2		
0,5 x 3		

V	A	mm ² /AWG
300	8	30 + 16

min 2 - max 20		
VE		
80		

Versione / **Version**
Version / **Version**


... **VO1** ...

P	L (mm)	X
3,5	3,5 x p	1,75
3,81	(3,81 x p)+0,79	2,3

MRT22

Blocco unico / **Single block**
Monobloc / **Einzelblock**

Poli / **Poles** / **2/10**
Pôles / **Polzahl**

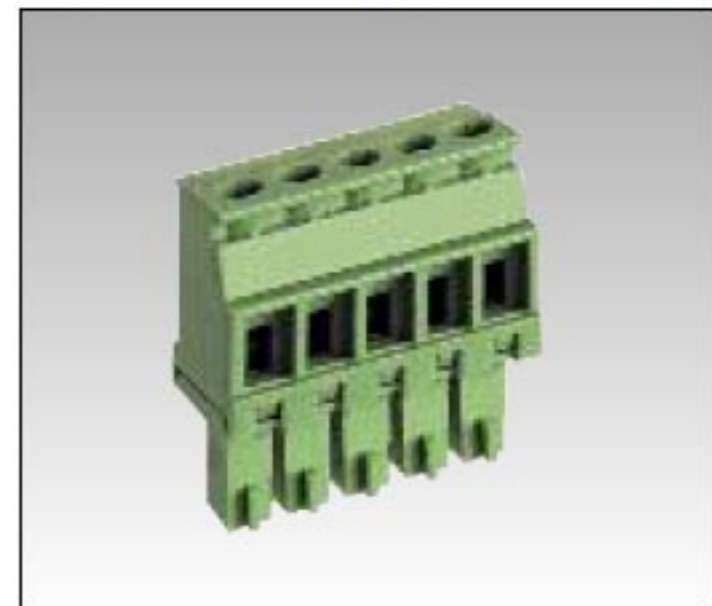

7	7,62
400	
500	
10	

0,2 + 1,0	0,2 + 1,0	0,2 + 1,0
30 + 16	30 + 16	30 + 16
5		
0,3	2	
110		
PA - UL 94 V0		
M2		
0,5 x 3		

V	A	mm ² /AWG
300	8	30 + 16

min 2 - max 10		
VE		
80		

Versione / **Version**
Version / **Version**

...

P	L (mm)	X
7	(7 x p)-3,5	1,75
7,62	(7,62 x p)-3,02	2,3

Passo / Pas	Pitch / Rastermaß	mm
Tensione nominale / Tension nominale / Corrente nominale / Intensité nominale	Rated Voltage / Bemessungsspannung / Rated Current / Bemessungsstrom	V / A

Tipo cavi / Type du conducteur	Types of cables / Leitungstypen	
Sezione nominale / Section nominale	Nominal cross section / Nennquerschnitt	mm² / AWG
Lunghezza spelatura / Longueur de dénudage	Stripping length / Abisolierlänge	mm
Coppia di torsione / Couple de serrage	Torque / Drehmoment	Nm / Lb-in
Temperatura / Température	Temperature / Temperatur	°C
Corpo isolante / Corps isolant	Housing / Isolierkörper	
Vite imperdibile / Vis imperdable	Captive screw / Unverlierbare Schraube	

IMQ	EN61984
VDE	EN61984
UL	UL1059
cUL	UL1059 + C22.2 n°158

Poli / Pôles	Poles / Polzahl	X
Colore standard / Coloris standard	Standard colour / Standardfarbe	Y
Altri dati / Autres données	Other information / Weitere Informationen	pag. / Seite

Ordinazione / **How to order**
Référence de commande / **Bestellschlüssel**

MRT8 P3,5 / X ... Y ...

Tipo	Passo	Poli	Versione	Colori	Numerazione
Type	Pitch	Poles	Version	Colors	Printing
Type	Pas	Pôles	Version	Couleurs	Marquage
Typ	Rastermaß	Polzahl	Version	Farben	Bedruckung

Altri colori a richiesta. / **Other colours on demand.**
Autres couleurs sur demande. / **Andere Farben bei Bedarf.**

VE GR NE AR BL RO