

HEADERS FOR P.C.B.

CONNETTORI MASCHIO PER C.S.

CONNECTEURS MÂLE POUR C.I.

STIFTFLEISTE FÜR LEITERPLATTEN

Pitch Pas	Passo Rastermaß	mm
Rated Voltage Tensione nominale	Tensione nominale Bernimmungsspannung	V
Rated Current Intensité nominale	Corrente nominale Bernimmungssstrom	A
Temperature Température	Temperatura Temperatur	°C
Housing Corps isolant	Corpo isolante Isolierkörper	

	IMQ	EN61984
	VDE	EN61984
	cUL	UL1059 + C22.2 n°158

Poles Pôles	Poli Polzahl	X
Colours Couleurs	Colori Farben	Y
Other information Autres données	Altri dati Weitere Informationen	p.

How to order Référence de commande			Ordinazione Bestellschlüssel		
MRT33 P7,62 / X			...	Y	N...
Type	Pitch	Poles	Version	Colors	Printing
Tipo	Passo	Poli	Versione	Colori	Numerazione
Type	Pas	Pôles	Version	Couleurs	Marquage
Typ	Rastermaß	Polzahl	Version	Farben	Bedruckung

MRT33

Single block · Blocco unico
Monobloc · Einzelblock



Poles · Poli · Pôles · Polzahl



7,62
500
10
110
PA - UL 94 V0

V	A	mm /AWG
300	8	30 ÷ 16

min 2 - max 6
VE
D/B4

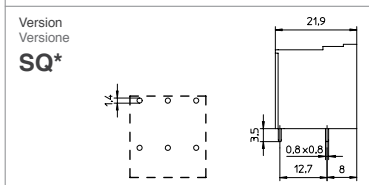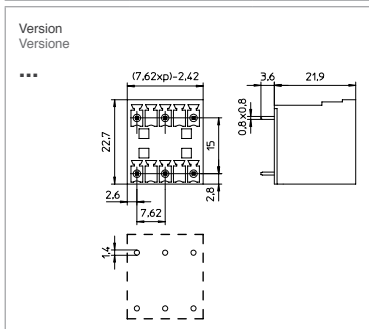


MRT33..SQ*

MRT33

Single block · Blocco unico
Monobloc · Einzelblock



Poles · Poli · Pôles · Polzahl

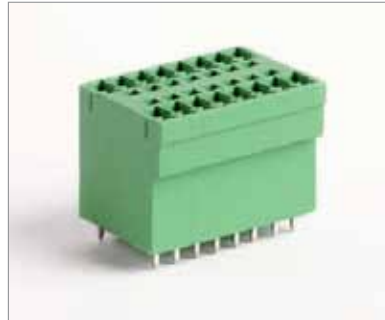

3,81
200
10
110
PA - UL 94 V0

V	A	mm /AWG
300	8	30 ÷ 16

min 2 - max 12
VE
D/B4

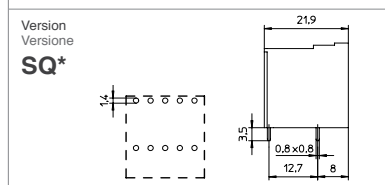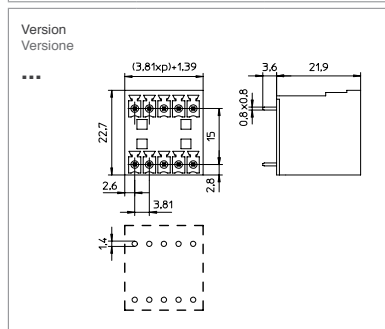

* SQ Version = Horizontal version