

Ground Terminal Blocks


A wide range of ground circuit terminal blocks are available to go with each of the different series of terminal blocks including both single circuits and multiple wires.

The ground circuit terminal blocks are molded in the internationally accepted colors of green and yellow. When attached to the DIN rail, terminated wires are connected directly to the DIN rail.



Terminal Width 8.2mm

ASIU SLKG6 N

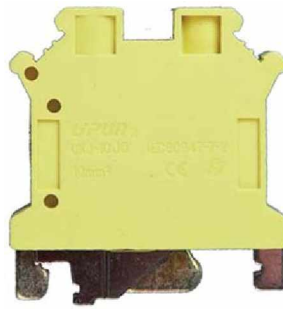

Terminal Width 10.2mm

ASIU SLKG10N



Terminal Width 12.2mm


ASIU SLKG16N



Terminal Width 15.2mm

ASIU SLKG35

SPECIFICATIONS								
Wire range, AWG	26-8		24-6		22-4		18-1/0	
Dimensions (L x H) mm	42.5 x 47		42.5 x 47		42.5 x 54		50 x 62	
Ordering Information	Order #	Pcs/ PkG	Order #	Pcs/ PkG	Order #	Pcs/ PkG	Order #	Pcs/ PkG
Ground Terminal Block w/ green-yellow housing	ASIU SLKG6 N	50	ASIU SLKG10N	50	ASIU SLKG16N	50	ASIU SLKG35	50
TB Markers								
Blank	ASIZB810B	10	ASIZB1010B	10	ASIZB1010B	10	ASIZB1010B	10
Custom	ASIZB8C...	...	ASIZB10C...	...	ASIZB10C...	...	ASIZB10C...	...
DIN Rail								
7.5 x 35mm slotted	PR005	1	PR005	1	PR005	1	PR005	1

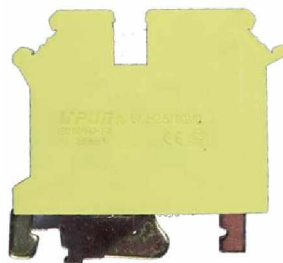

Terminal Width 6.2mm

ASIMBK5EZPE



Terminal Width 8.2mm

ASIMSLKG6



Terminal Width 4.2mm

ASIMT1.5PE



Terminal Width 4.2mm

ASIMT1.5TWINPE

SPECIFICATIONS								
Wire range, AWG	26-14		26-8		30-14		22-4	
Dimensions (L x H) mm	28 x 32		39 x 36		22 x 23.5		42.5 x 54	
Ordering Information	Order #	Pcs/ PkG	Order #	Pcs/ PkG	Order #	Pcs/ PkG	Order #	Pcs/ PkG
Ground Terminal Block w/ green-yellow housing	ASIMBK5EZPE	50	ASIMSLKG6	50	ASIMT1.5PE	50	ASIMT1.5TWINPE	50
TB Markers								
Blank	ASIZB610B	10	ASIZB810B	10	ASIZBFM4B	10	ASIZBFM4B	10
Custom	ASIZB6C...	...	ASIZB8C...	...	ASIZBFM4C...	...	ASIZBFM4C...	...
DIN Rail								
7.5 x 35mm slotted 15mm mini slotted	PR010	1	PR010	1	PR010	1	PR010	1