


LED PILOT LIGHT Ø22



DESCRIPTION	POWER SUPPLY	CODE	WEIGHT grammi	MIN. PACK QUANTITY
SINGLE LED INDICATOR X1 — ⊗ — X2	AC/DC 6V 1	PLML 2 L6	15	10
	AC/DC 12V 1	PLML 2 L12	15	10
	AC/DC 24V	PLML 2 L24	15	10
	AC/DC 48V	PLML 2 L48	15	10
	AC/DC 110V	PLML 2 L110	15	10
	AC 220V	PLML 2 L220	15	10
	AC 380V 1	PLML 2 L380	15	10


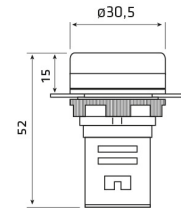


COMPLY WITH RULES

EN60947-5-1 / GB14048.5

DIAGRAM

Operational temperature	°C	-5 +40
Operational umidity		45% ... 90%
AC rated frequency	Hz	50/60
Rated insulation voltage	1 min V	2500V
Over voltage category	EN60947.1	III
Pollution grade	EN60947.1	3
Protection degree	EN60529	IP65, IP2X terminals
Connection:		
Terminal block caliber		A2
Terminal screw		M3,5
Flexible and solid conductor section	min/max	n. 1 1/2,5 mm ² - n. 2 1/2,5 mm ²
Rated operational voltage Ue	AC/DC V	6, 12, 24, 48, 110
	AC V	220 - 380
Rated operational voltage Ie	mA	≤80 6,12V
	mA	≤20 24, 48, 110, 220, 380V
Electrical life	h	≥30.000
Brightness	cd/m ²	100
Mounting	mm	Ø22,5

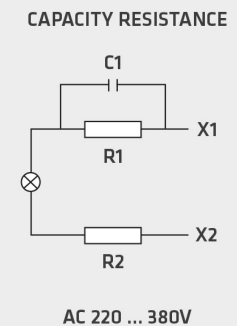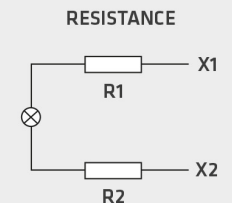

1 On demand execution **2** Insert lens colour code: ■ ■ ■ ■