
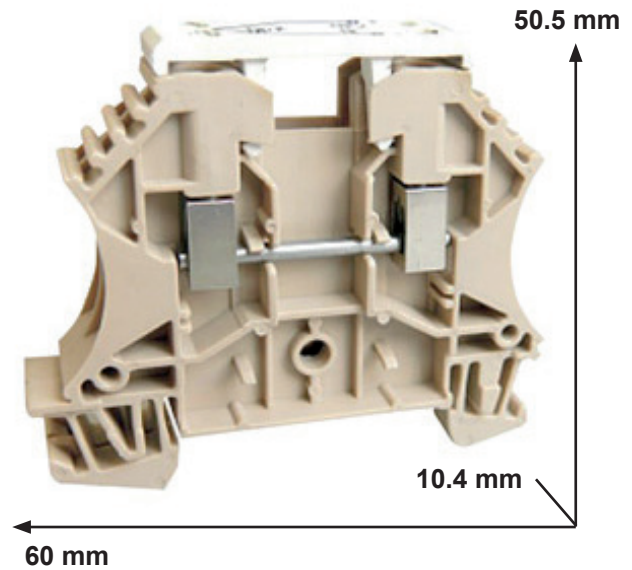


UKJ-W2.5/TC-K, Thermocouple Terminal Block

- Low voltage thermocouple terminal block for use with temperature measuring circuits
- Special current bars ensure that no false signals are transmitted as would be the case with standard terminal blocks.

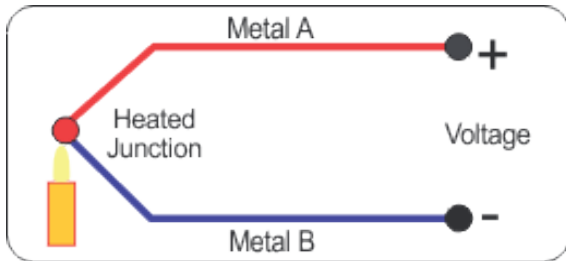

Part Number:	Type:	Metal A:	Metal B:
ASI431016	UKJ-W2.5/TC-K	Nickel-Chromium	Nickel-Aluminum
ASI431019	UKJ-W2.5/TC-T	Copper	Copper-Nickel
ASI431020	UKJ-W2.5/TC-J	Iron	Copper-Nickel
ASI431021	UKJ-W2.5/TC-SR	(S)Platinum-10% Rhodium	Platinum
		(R)Platinum-13% Rhodium	Platinum
ASI431022	UKJ-W2.5/TC-P	Palladium-55%, Platinum-31%, Gold-14%	Gold-65% Palladium-35%
ASI431023	UKJ-W2.5/TC-E	Nickel-Chromium	Copper-Nickel

Dimensions and Ratings:	
H x W x D	50.5 x 10.4 x 60 mm
Torque	0.6-0.8Nm
Stripping Length	10 mm
Voltage	55 Vdc
Current	1A
Wire Range	26-14 AWG