

NEMA Type 4X

Quick Release Latch Fiberglass Enclosures

Flat Cover

STANDARD FEATURES

- Twelve standard sizes available
- Padlockable quick release latch for quick entry
- Full length stainless steel hinged cover
- Integral mounting flange
- Cover opens full 180°+
- Mounting bosses with threaded brass inserts for mounting panel installation
- Poured polyurethane gasket provides water-tight, dust-tight seal
- Light weight and impact resistant

DESIGN OPTIONS

- Mounting panels
- Drilled entries and cut-outs available
- Molded in custom colors
- Silk screening, paint, and decals

MATERIAL




- Hot compression molded fiberglass reinforced polyester (thermoset)
- Non-corrosive and UV resistant
- Smooth surface, no color variations, swirls, or color pockets
- Non-flame propagating and chemical resistant
- Color described as Light Gray

CERTIFICATIONS

- UL 50
- CSA Std 22.2 No. 94
- NEMA Type 1, 2, 4X, 6P, 12
- Temperature Range - 40° C to +120° C (-40° F to +150° F)
- Flammability Rating UL94-5V



NEMA Type 4X

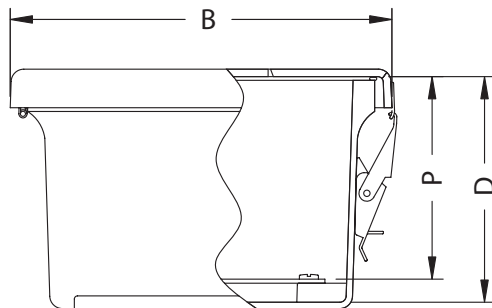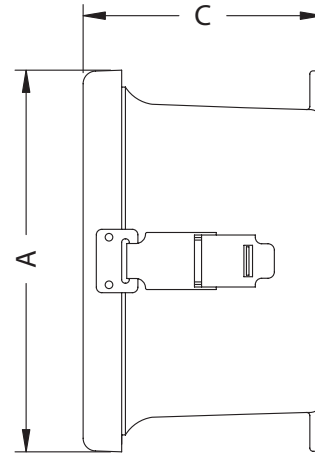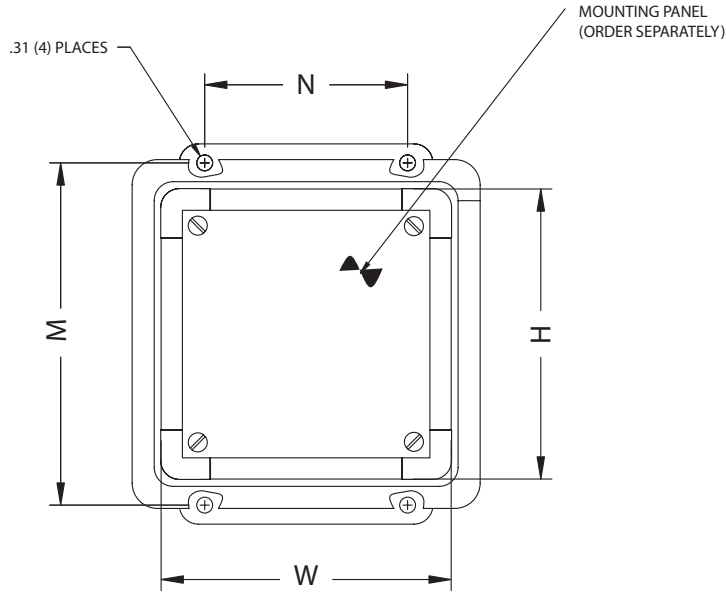

FIBERGLASS

Catalog #	Overall Dimensions			Inside Dimensions			Mounting Dimensions			Weight Lbs.	Panel Cat #	Panel Dim.	
	A	B	C	H	W	D	M	N	P				
N4X-FG-060404CHQR	7.50	5.43	4.75	5.84	3.85	4.45	6.75	2.00	4.00	2.50 lbs.	BP64A	4.88	2.88
N4X-FG-060604CHQR	7.50	7.50	4.75	5.72	5.72	4.45	6.75	4.00	4.00	2.75 lbs.	BP66A	4.88	4.88
N4X-FG-080604CHQR	9.62	7.50	4.74	7.73	5.74	4.45	8.88	4.00	4.00	3.50 lbs.	BP86A	6.88	4.88
N4X-FG-080804CHQR	9.56	9.38	4.89	7.73	7.73	4.64	8.75	6.00	4.06	4.00 lbs.	BP88A	6.88	6.88
N4X-FG-100804CHQR	11.62	9.41	4.25	9.73	7.73	3.98	10.75	6.00	3.50	5.00 lbs.	BP108A	8.88	6.88
N4X-FG-121005CHQR	13.56	11.43	5.21	11.79	9.80	4.94	12.75	8.00	4.50	6.50 lbs.	BP1210A	10.88	8.88
N4X-FG-121206CHQR	13.56	13.38	6.36	11.70	11.70	6.11	12.75	10.00	5.53	3.20 lbs.	BP1212A	10.88	10.88
N4X-FG-140706CHQR	15.87	8.75	6.81	14.00	7.00	6.56	15.00	5.00	6.12	6.25 lbs.	BP147A	12.88	5.88
N4X-FG-141206CHQR	15.50	13.50	6.25	13.53	11.55	5.94	14.62	10.00	5.37	8.50 lbs.	BP1412A	12.88	10.88
N4X-FG-161406CHQR	17.53	15.46	6.23	15.63	13.60	5.94	16.75	12.00	5.36	11.50 lbs.	BP1614A	14.88	12.88
N4X-FG-181608CHQR	19.62	17.61	8.82	17.69	15.69	8.45	18.88	12.00	7.99	19.25 lbs.	BP1816A	16.88	14.88
N4X-FG-201608CHQR	22.00	17.68	8.83	19.72	15.72	8.45	21.25	10.00	8.00	20.25 lbs.	BP2016A	18.88	14.88

All measurements are in inches