

## Large Control Fiberglass Enclosures

### **STANDARD FEATURES**

- Ten standard sizes available
- Twist latch for quick entry
- Raised cover for additional usable depth
- Stainless steel hinged cover
- Integral mounting flange
- Built in padlock hasp
- Mounting bosses with threaded brass inserts for mounting panel installation
- Poured polyurethane gasket provides water-tight, dust-tight seal
- Light weight and impact resistant

### **DESIGN OPTIONS**

- Mounting panels
- Drilled entries and cut-outs available
- Molded in custom colors
- Silk screening, paint, and decals

### **MATERIAL**




- Hot compression molded fiberglass reinforced polyester (thermoset)
- Non-corrosive and UV resistant
- Smooth surface, no color variations, swirls, or color pockets
- Non-flame propagating and chemical resistant
- Color described as Light Gray

### **CERTIFICATIONS**

- UL 50
- CSA Std 22.2 No. 94
- NEMA Type 1, 3, 4X, 6P, 12
- Temperature Range - 40° C to +120° C (-40° F to +250° F)
- Flammability Rating UL94-5V



# NEMA Type 4X

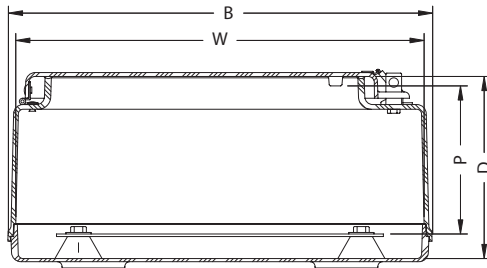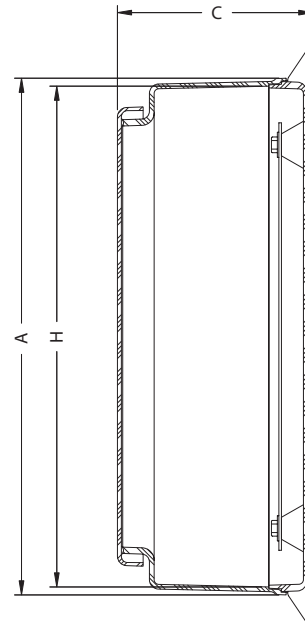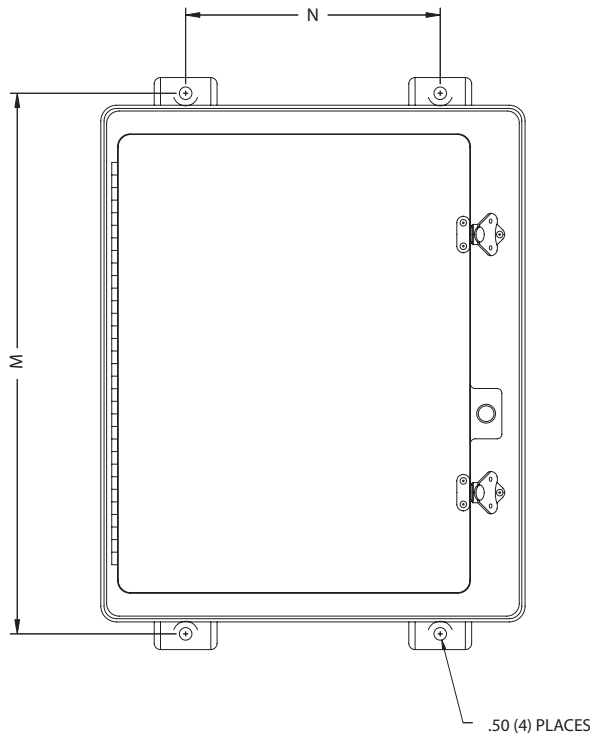

Fiberglass

## FIBERGLASS

	A	B	C	H	W	D	M	N	P	Lbs.		
N4X-FG-201606CH	22.75	16.87	7.77	19.70	16.04	7.24	21.50	10.12	6.26	17 lbs.	BPN2016A	17.00 13.00
N4X-FG-201608CH	22.75	16.87	9.77	19.70	16.04	9.24	21.50	10.12	8.26	22 lbs.	BPN2016A	17.00 13.00
N4X-FG-201612CH	22.75	16.87	13.77	19.70	16.04	13.24	21.50	10.12	12.26	24 lbs.	BPN2016A	17.00 13.00
N4X-FG-242008CH	27.00	21.24	9.90	24.05	20.39	9.25	25.75	14.00	8.25	32 lbs.	BP2420A	21.00 17.00
N4X-FG-242410CH	27.00	25.24	11.90	24.05	24.39	11.25	25.75	17.87	10.25	42 lbs.	BP2424A	21.00 21.00
N4X-FG-302410CH	33.41	26.32	11.95	30.46	25.47	11.27	32.25	18.50	10.27	50 lbs.	BP3024A	27.00 21.00
N4X-FG-302412CH	33.41	26.32	13.79	30.46	25.47	13.10	32.25	18.50	12.10	54 lbs.	BP3024A	27.00 21.00
N4X-FG-363010CH	39.31	32.50	12.05	36.31	31.69	11.36	38.13	23.88	10.36	78 lbs.	BP3630A	33.00 27.00
N4X-FG-363012CH	39.31	32.50	14.05	36.31	31.69	13.36	38.13	23.88	12.36	81 lbs.	BP3630A	33.00 27.00
N4X-FG-483616CH	51.29	36.62	17.93	48.33	36.22	17.25	50.12	29.25	16.25	108 lbs.	BP4836A	45.00 33.00

All measurements are in inches