

Quick Release Latch Fiberglass Enclosures

Raised Cover

STANDARD FEATURES

- Eleven standard sizes available
- Padlock quick release latch for quick entry
- Raised cover for additional usable depth
- Full length stainless steel hinged cover
- Integral mounting flange
- Cover opens full 180°+
- Mounting bosses with threaded brass inserts for mounting panel installation
- Poured polyurethane gasket provides water-tight, dust-tight seal
- Light weight and impact resistant

DESIGN OPTIONS

- Mounting panels
- Drilled entries and cut-outs available
- Molded in custom colors
- Silk screening, paint, and decals

MATERIAL



- Hot compression molded fiberglass reinforced polyester (thermoset)
- Non-corrosive and UV resistant
- Smooth surface, no color variations, swirls, or color pockets
- Non-flame propagating and chemical resistant
- Color described as Light Gray

CERTIFICATIONS

- UL 50
- CSA Std 22.2 No. 94
- NEMA Type 1, 3, 4X, 6P, 12
- Temperature Range - 40° C to +120° C (-40° F to +250° F)
- Flammability Rating UL94-5V



NEMA Type 4X

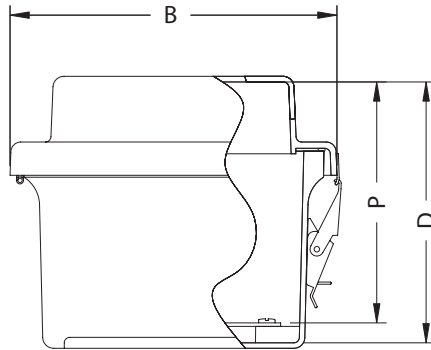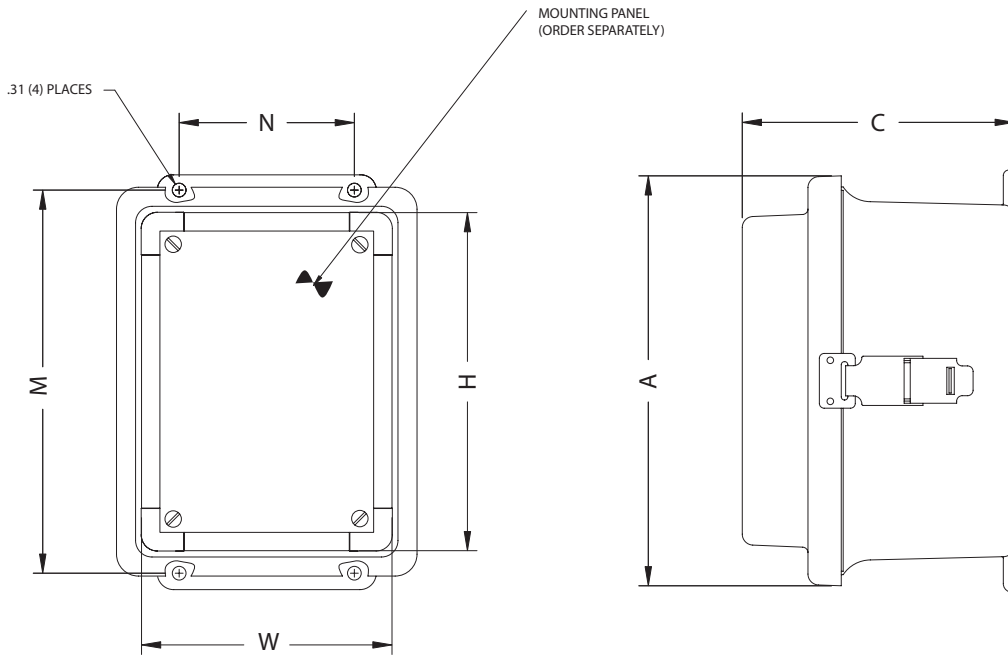

FIBERGLASS

Catalog #	Overall Dimensions			Inside Dimensions			Mounting Dimensions			Weight	Panel Cat #	Panel Dim.	
	A	B	C	H	W	D	M	N	P				
N4X-FG-060404RCHQR	7.50	5.47	6.22	5.84	3.85	5.95	6.75	2.00	5.49	2.50 lbs.	BP64A	4.88	2.88
N4X-FG-060604RCHQR	7.50	7.52	6.22	5.72	5.72	5.95	6.75	4.00	5.49	2.75 lbs.	BP66A	4.88	4.88
N4X-FG-080604RCHQR	9.62	7.46	6.22	7.73	5.74	5.95	8.88	4.00	5.49	3.50 lbs.	BP86A	6.88	4.88
N4X-FG-080804RCHQR	9.56	9.38	6.26	7.73	7.73	6.01	8.75	6.00	5.43	4.00 lbs.	BP88A	6.88	6.88
N4X-FG-100804RCHQR	11.62	9.37	6.61	9.73	7.73	6.36	10.75	6.00	5.91	5.00 lbs.	BP108A	8.88	6.88
N4X-FG-121005RCHQR	13.56	11.43	6.61	11.79	9.80	6.32	12.75	8.00	5.87	6.50 lbs.	BP1210A	10.88	8.88
N4X-FG-121206RCHQR	13.56	13.38	7.73	11.70	11.70	7.48	12.75	10.00	6.90	6.50 lbs.	BP1212A	10.88	10.88
N4X-FG-141206RCHQR	15.50	13.50	7.69	13.53	11.55	7.45	14.62	10.00	6.87	8.50 lbs.	BP1412A	12.88	10.88
N4X-FG-161406RCHQR	17.53	15.46	7.71	15.63	13.60	7.45	16.75	12.00	6.87	11.50 lbs.	BP1614A	14.88	12.88
N4X-FG-181608RCHQR	19.62	17.61	10.62	17.69	15.69	10.31	18.88	12.00	9.86	19.25 lbs.	BP1816A	16.88	14.88
N4X-FG-201608RCHQR	22.00	17.68	10.64	19.72	15.72	10.33	21.25	10.00	9.87	20.25 lbs.	BP2016A	18.88	14.88

All measurements are in inches