

# 150 Amp "Mini" Devices


## CAM Technology

SINGLE PIN CONNECTORS

### CLM Series Panel Mount

"Super Tough" Nylon Housing (Hard Shell)

Standard products supplied with self-threading screws. Optional mounting holes for 10-32 screws shown at right. Add "X" suffix code.

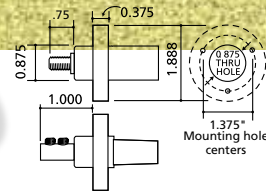

Amps/Voltage	Accepts Wire	CLM Female	CLM Male
150A / 600V	3/4" - 8 THREADED STUD	<b>CLMFRS</b>	<b>CLMMRS</b>
150A / 600V	#8 - #2 DOUBLE SET SCREW	<b>CLMFR2</b>	<b>CLMMR2</b>



### CLSM Series Panel Mount

Santoprene Housing

**NEW!**




150A / 600V	3/4" - 8 THREADED STUD	<b>CLSMFRS</b>	<b>CLSMMRS</b>
150A / 600V	#8 - #2 DOUBLE SET SCREW	<b>CLSMFR2</b>	<b>CLSMMR2</b>



### Cam Reducers

Amps/Voltage	Part No.
400A F to 150A F	<b>CLMADFF</b>
400A M to 150A F	<b>CLMADMF</b>
400A F to 150A M	<b>CLMADFM</b>
400A M to 150A M	<b>CLMADMM</b>
<b>NEW!</b> 400A / 600V M to three 150A / 600V F	<b>CLMAD3F</b>
400A / 600V M to three 150A / 600V F	<b>CLMAD3FST</b>

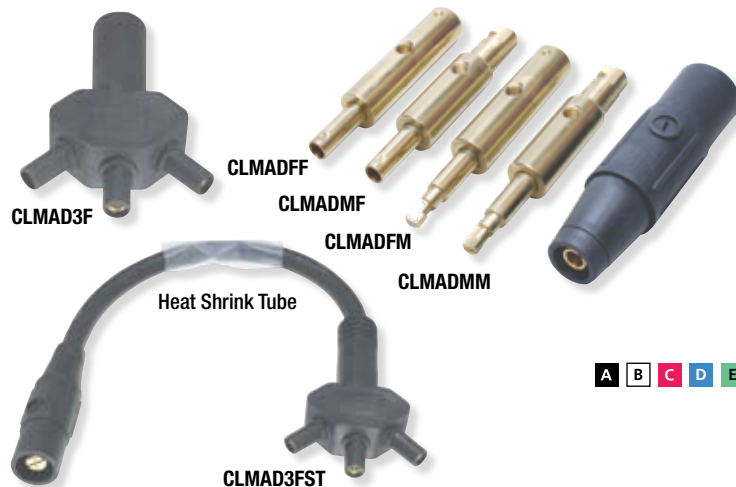

### Couplers & Ts

150A / 600V	M - M	<b>CLMMM</b>	Turnaround
150A / 600V	F - F	<b>CLMFF</b>	Paralleling T
150A / 600V	M - M - F	<b>CLMPT</b>	Tapping T
150A / 600V	M - F - F	<b>CLMTT</b>	



### Cam Technology Product Number Suffix Codes

Series CL, CLS, CLM + R = Panel Mount + Color + .OEM  
 AD = Adapter  
 F = Female  
 M = Male

Example: CLMADMM-C.OEM