



Empire Series: Wall Mount



APPLICATION

- Designed to insulate and house electrical and electronic controls, instruments or components for indoor and outdoor applications
- Especially well suited for high temperature or corrosive environments
- Protects from dirt, dust, oil and water

STANDARDS

- UL Types 1, 4, and 4X
- CSA Types 1, 4, and 4X
- NEMA Types 1, 4, and 4X
- IEC 60529 Type IP66

CONSTRUCTION


- Durable, corrosion resistant Ultraguard® fiberglass material construction
- Flexible, self-gripping gasket compresses over flange for tight seal and needs only three closure twist latches to meet NEMA 4X requirements (AM6036 requires 4 latches)
- Heavy-duty continuous 304 stainless steel hinge
- Ultraguard® fiberglass material has UV inhibitors which provide ideal protection from outdoor weathering

ACCESSORIES

- Optional painted carbon steel back panels
- Optional thermal management products (See pages 102-103.)
- Optional print pocket

MODIFICATIONS

See page 106

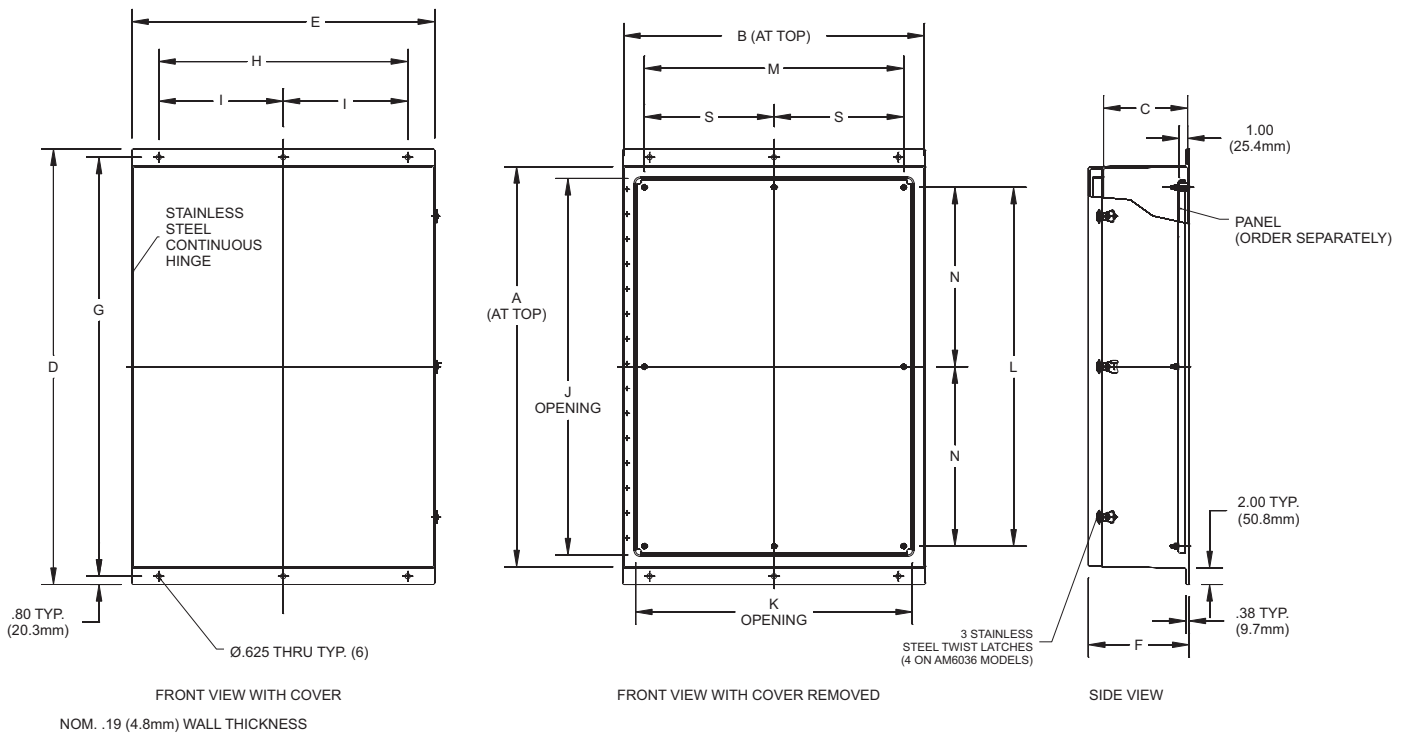

Part No.	A	B	C	D	E	F	G	H	I	J	K	L	M
AM363012L	36.25 921mm	30.25 768mm	10.16 258mm	40.50 1,029mm	31.15 791mm	12.03 306mm	38.90 988mm	24.00 610mm	12.00 305mm	33.50 851mm	27.50 699mm	31.25 794mm	25.25 641mm
AM363016L	36.04 915mm	30.04 763mm	14.16 360mm	40.50 1,029mm	31.15 791mm	16.03 407mm	38.90 988mm	24.00 610mm	12.00 305mm	33.50 851mm	27.50 699mm	31.25 794mm	25.25 641mm
AM363612L	36.25 921mm	36.25 921mm	10.16 258mm	40.50 1,029mm	37.15 944mm	12.03 306mm	38.90 988mm	30.00 762mm	15.00 381mm	33.50 851mm	33.50 851mm	31.25 794mm	31.25 794mm
AM363616L	36.04 915mm	36.04 915mm	14.16 360mm	40.50 1,029mm	37.15 944mm	16.03 407mm	38.90 988mm	30.00 762mm	15.00 381mm	33.50 851mm	33.50 851mm	31.25 794mm	31.25 794mm
AM483612L	48.25 1,226mm	36.25 921mm	10.16 258mm	52.50 1,334mm	37.15 944mm	12.03 306mm	50.90 1,293mm	30.00 762mm	15.00 381mm	45.50 1,156mm	33.50 851mm	43.25 1,099mm	31.25 794mm
AM483616L	48.04 1,220mm	36.04 915mm	14.16 360mm	52.50 1,334mm	37.15 944mm	16.03 407mm	50.90 1,293mm	30.00 762mm	15.00 381mm	45.50 1,156mm	33.50 851mm	43.25 1,099mm	31.25 794mm
AM603612L	60.25 1,530mm	36.25 921mm	10.16 258mm	64.50 1,638mm	37.15 944mm	12.03 306mm	62.90 1,598mm	30.00 762mm	15.00 381mm	57.50 1,461mm	33.50 851mm	55.25 1,403mm	31.25 794mm
AM603616L	60.04 1,525mm	36.04 915mm	14.16 360mm	64.50 1,638mm	37.15 944mm	16.03 407mm	62.90 1,598mm	30.00 762mm	15.00 381mm	57.50 1,461mm	33.50 851mm	55.25 1,403mm	31.25 794mm

All dimensions are in inches unless otherwise noted.

Part No.	N	S	# PANEL MOUNT STUDS	# OF TWIST LATCHES
AM363012L	15.63 397mm	12.63 321mm	6	3
AM363016L	15.63 397mm	12.63 321mm	6	3
AM363612L	15.63 397mm	15.63 397mm	8	3
AM363616L	15.63 397mm	15.63 397mm	8	3
AM483612L	21.63 549mm	15.63 397mm	8	3
AM483616L	21.63 549mm	15.63 397mm	8	3
AM603612L	27.63 702mm	15.63 397mm	8	4
AM603616L	27.63 702mm	15.63 397mm	8	4

All dimensions are in inches unless otherwise noted.

Optional Carbon Steel Back Panels		
Part No.	Height	Width
P3630CS	33.00 833mm	27.00 686mm
P3636CS	33.00 833mm	33.00 833mm
P4836CS	45.00 1143mm	33.00 833mm
P6036CS	57.00 1448mm	33.00 833mm

All dimensions are in inches unless otherwise noted.

