


FEED-THROUGH DOUBLE LEVEL 35 or 32mm DIN Rail

Altech double level terminals are the answer to high wiring density problems posed by certain unavoidable wiring arrangements. Double level terminals have the following advantages:



- Double wiring density available without extension of mounting rails.
- Interconnection/shorting can be done at both levels.
- Marking/identification by marking tags possible at both levels.

 
 
 
CDL4U(I.S) internally shorted double level terminals are useful for distribution applications by using shorting links at lower levels.

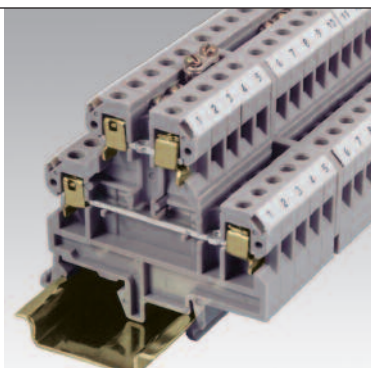

CDL4U

CDL4U(I.S)

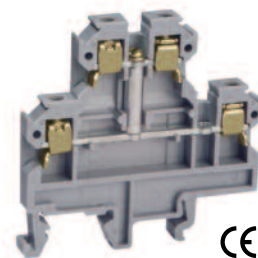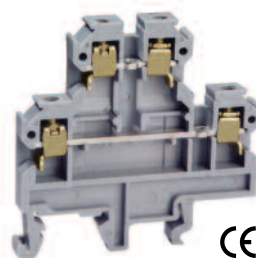

Terminal Width	6 mm			6 mm		
Height x Length	54 x 55.5 mm			54 x 55.5 mm		
Stripping Length	9 mm			9 mm		
Insulation Material	Polyamide 6.6			Polyamide 6.6		
Type of Connection	4 screw clamps & 2 tapped holes for cross connection			4 screw clamps & 1 tapped hole for cross connection		
Approvals	  			  		
Wire Range	22-10 AWG	0.5-4 sq.mm	22-10 AWG	22-10 AWG	0.5-4 sq.mm	22-10 AWG
Voltage Rating	300V	400 V	600 V	300 V	400 V	600 V
Current Rating	35 A	32 A	35 A	35 A	32 A	35 A
Torque	7 lb-in	0.5 Nm	7 lb-in	7 lb-in	0.5 Nm	7 lb-in
	Cat. No.	Std. Pk.		Cat. No.	Std. Pk.	
Terminal Block	CDL4U	100		CDL4U(I.S)	100	
End Plate 	EPCDL4U	50		EPCDL4U	50	
Separator Plate 	SPCDL4U	100		SPCDL4U	100	
DIN Rail for ordering information refer to page 62						
End Stop for ordering information refer to page 63 	CA702	50		CA702	50	
	CA802	50		CA802	50	
Internal Jumper 	2 pole	CA727/2	100	2 pole	CA727/2	100
	3 pole	CA727/3	50	3 pole	CA727/3	50
	4 pole	CA727/4	50	4 pole	CA727/4	50
	10 pole	CA727/10	10	10 pole	CA727/10	10
Insulated Internal Jumper 	2 pole	CA747/2	100	2 pole	CA747/2	100
	3 pole	CA747/3	50	3 pole	CA747/3	50
	4 pole	CA747/4	50	4 pole	CA747/4	50
	10 pole	CA747/10	10	10 pole	CA747/10	10
Current Bars 	2 pole	CA703/1	100	2 pole	CA703/1	100
	3 pole	CA704/1	100	3 pole	CA704/1	100
	4 pole	CA705/1	100	4 pole	CA705/1	100
	10 pole	CA732/10	100	10 pole	CA732/10	100
	10 pole (breakable)	CA732/10-A	100	10 pole (breakable)	CA732/10-A	100
	100 pole	CA732/100	10	100 pole	CA732/100	10
Shorting Sleeve & Screw 		CA607/S/Q	100		CA607/S/Q	100
External Jumper 	2 pole	CA714/2	100	2 pole	CA714/2	100
	3 pole	CA714/3	100	3 pole	CA714/3	100
	4 pole	CA714/4	50	4 pole	CA714/4	50
	10 pole	CA714/10	25	10 pole	CA714/10	25
Marking Tags (MT Type) 	MT2	100		MT2	100	



COLOR BLOCKS (other than grey standard)

When ordering please add color suffix to Cat. No.

Example: CTS2.5U-N/R

Color	Ordering Suffix
Red	R
Blue	BU
Black	BL
Orange	O
Green	G
Yellow	Y
White	W
Beige	BG
Dark Brown	DB