

ANT-PA-2419

2.4~2.5GHz Outdoor Panel Antenna 19dBi




Features

- ▶ Superior Performance
- ▶ Lightweight Antenna
- ▶ Good Appearance Designs
- ▶ DC Short Lightning Protection
- ▶ Installed for Vertical or Horizontal Polarization
- ▶ Aluminum Built Support
- ▶ Up and Down Adjustment Support
- ▶ Outdoor Antenna for Public Hot-Spots
- ▶ Includes Tilt and Swivel Mast Mount Brackets
- ▶ RoHS Compliant

INTRODUCTION

Antaira Technologies ANT-PA-2419 is a directional panel antenna that can broadcast WiFi signals on the 2.4GHz frequency. The ANT-PA-2419 is an outdoor, waterproof antenna. The 14dBi antenna has a standard female N-type connector that can be connected to most industrial wireless access points, clients, bridge or bluetooth device. The ANT-PA-2419 works with IEEE 802.11b, IEEE 802g, IEEE 802n. A N-type to SMA conversion cable is available.

NETWORK ANALYZER TEST REPORT

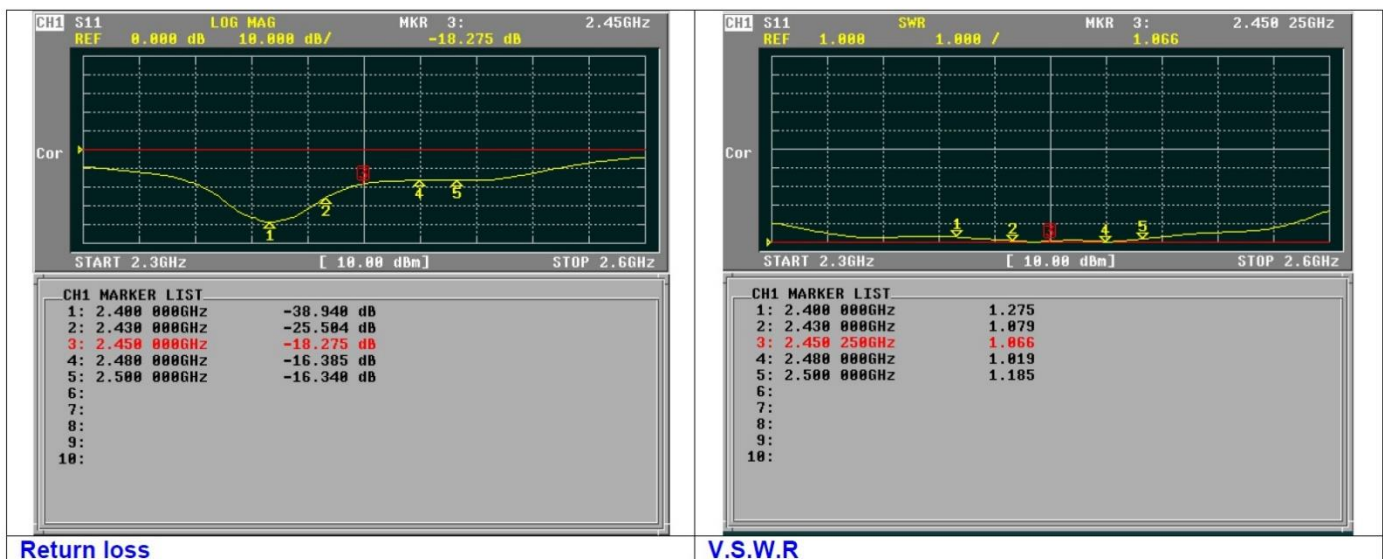

SPECIFICATIONS

Frequency	2.4~2.5GHz	Beam Width	H: 17° / V: 17°
VSWR	≤ 1.5	Connector	N Female
Gain	19dBi	Operation Temp	-40°~80°C
Polarization	Vertical or Horizontal	Dimension	370 x 370 mm
Power Handling	50 Watts	Mounting	32~45 mm (1.2~1.75 inch)
Impedance	50 Ω	Weight	1030g

ORDERING INFO

ANT-PA-2419 2.4~2.5GHz Outdoor Panel Antenna 19dBi