

# Cable Connectors

## Two Screw Clamp and 90° Squeeze Connectors

For Armored Cable and Flexible Metal Conduit

**NEC/CEC:**  
Listed for Ordinary Locations

### Application:

- To ground and secure Armored Cable and Flexible Metal Conduit to boxes and enclosures.

### Features

- Male hubs - NPS.
- Provided with center stop.
- Available with insulated throats.
- Furnished with locknuts.
- Also suitable for NM and SE cable.

### Standard Materials

- Malleable iron



### Standard Finishes

- Zinc electroplated


### NEC/CEC Certifications and Compliances

- UL Standard: ANSI/UL 514B (1203)
- UL Listed: E-11853
- CSA Standard C22.2 No. 18
- CSA Certified: 009795
- NEMA: FB-1


### Illustrated Dimensions

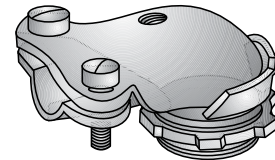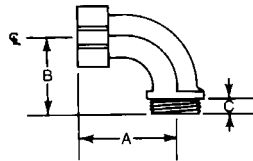


Type ACV-938

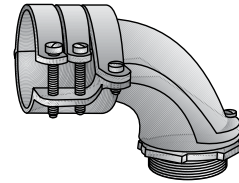

Type AC-150 — Type AC-200

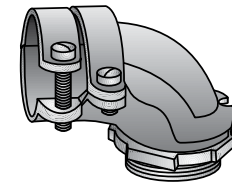

Type ACV-50 — Type AC-125

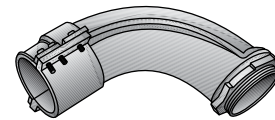

Type AC-250 — Type AC-400

Trade Size (Inches)	Dimensions in Millimeters (Inches)				Flex Opening	Catalog Number	Insulated Throat Catalog Number
	A	B	C				
3/8 (1/2 KO)	33.27 (1.31)	20.57 (0.81)	11.18 (0.44)		9.14 - 16.76 (0.36 - 0.66)	<b>ACV-938</b>	<b>ACV-938T</b>
1/2	44.45 (1.75)	26.92 (1.06)	11.18 (0.44)		19.81 - 24.13 (0.78 - 0.95)	<b>ACV-50</b>	<b>ACV-50T</b>
3/4	45.97 (1.81)	28.70 (1.13)	11.18 (0.44)		23.11 - 25.91 (0.91 - 1.02)	<b>ACV-75</b>	<b>ACV-75T</b>
1	52.32 (2.06)	39.62 (1.56)	14.22 (0.56)		31.75 - 35.05 (1.25 - 1.38)	<b>AC-100</b>	<b>AC-100T</b>
1-1/4	71.37 (2.81)	50.80 (2.00)	14.22 (0.56)		35.81 - 41.4 (1.41 - 1.63)	<b>AC-125</b>	<b>AC-125T</b>
1-1/2	96.77 (3.81)	71.37 (2.81)	14.22 (0.56)		44.45 - 50.8 (1.75 - 2.00)	<b>AC-150</b>	<b>AC-150T</b>
2	120.65 (4.75)	82.55 (3.25)	17.53 (0.69)		55.63 - 42.93 (2.19 - 1.69)	<b>AC-200</b>	<b>AC-200T</b>
2-1/2	158.75 (6.25)	109.47 (4.31)	22.35 (0.88)		69.85 - 76.20 (2.75 - 3.00)	<b>AC-250</b>	<b>AC-250T</b>
3	184.15 (7.25)	130.30 (5.13)	25.40 (1.00)		82.55 - 88.9 (3.25 - 3.50)	<b>AC-300</b>	<b>AC-300T</b>
3-1/2	260.35 (10.25)	196.85 (7.75)	31.75 (1.25)		93.98 - 105.66 (3.70 - 4.16)	<b>AC-350</b>	<b>AC-350T</b>
4	330.20 (13.00)	247.65 (9.75)	31.75 (1.25)		104.39 - 115.82 (4.11 - 4.56)	<b>AC-400</b>	<b>AC-400T</b>