

WYL/YL Type Unflanged Junction or Pull Boxes

Raintight, Watertight, Dust-Tight

Cast Iron Box For Surface Mounting.

NEC/CEC:
NEMA/CSA Type 1, 2, 3, 3R, 3S, 4, 5, 12, 12K,
13

CEC:
Class II, Division 1 and 2
Class III

Applications

- These boxes are listed by Underwriters Laboratories and Canadian Standards Association as Type 4.
- They are suitable for use indoors, outdoors, or where subject to rain, dripping or splashing water or hose-directed water.

Features

- Mounting lugs are standard.
- Boxes have a post in each corner and allowances must be made for them when conduit entrances are to be located close to a corner.
- Neoprene gasket – between cover and box.
- Wide selection of sizes and locations for drilled-and-tapped and slip-hole conduit entrances.

Standard Materials

- Box and cover: cast iron
- Gasket: neoprene
- Screws: stainless steel

Standard Finishes


- Box and cover: hot dip galvanized

Options

- For additional options see *Ordering Information* pages.

NEC/CEC Certifications and Compliances

- UL Standard: UL 514A, UL 50, UL 50E
- UL Listed: E24824
- CSA Standard: C22.2 No. 18.1, C22.2 No. 94.1, C22.2 No. 94.2, C22.2 No. 25
- CSA Certified: 020945

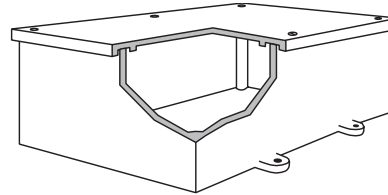

L	Inside Dimensions mm (in)				Approximate Wall Thickness ① mm (in)	Appleton Catalog Number	O-Z/Gedney Catalog Number
	x	W	x	D			
101.6 (4.00)	x	101.6 (4.00)	x	101.6 (4.00)	6.35 (0.2500)	WYL-040404	YL-040404
152.4 (6.00)	x	152.4 (6.00)	x	101.6 (4.00)	7.94 (0.3125)	WYL-060604	YL-060604
203.2 (8.00)	x	203.2 (8.00)	x	101.6 (4.00)	7.94 (0.3125)	WYL-080804	YL-080804
203.2 (8.00)	x	203.2 (8.00)	x	152.4 (6.00)	7.94 (0.3125)	WYL-080806	YL-080806
254.0 (10.00)	x	254.0 (10.00)	x	101.6 (4.00)	7.94 (0.3125)	WYL-101004	YL-101004
304.8 (12.00)	x	304.8 (12.00)	x	203.2 (8.00)	7.94 (0.3125)	WYL-121208	YL-121208
406.4 (16.00)	x	304.8 (12.00)	x	203.2 (8.00)	7.94 (0.3125)	WYL-161208	YL-161208
457.2 (18.00)	x	304.8 (12.00)	x	254.0 (10.00)	9.53 (0.3750)	WYL-181210	YL-181210
457.2 (18.00)	x	457.2 (18.00)	x	152.4 (6.00)	7.94 (0.3125)	WYL-181806	YL-181806
457.2 (18.00)	x	457.2 (18.00)	x	304.8 (12.00)	11.11 (0.4375)	WYL-181812	YL-181812
609.6 (24.00)	x	609.6 (24.00)	x	304.8 (12.00)	11.11 (0.4375)	WYL-242412	YL-242412
914.4 (36.00)	x	609.6 (24.00)	x	304.8 (12.00)	11.11 (0.4375)	WYL-362412	YL-362412

① Measured 50.8 mm (2.00") up from back of box.