

GS Conduit Outlet Boxes, Covers and Hangers

UNILETS™ for use with Threaded Rigid Metal Conduit and IMC.

NEC:
Rated for Ordinary Locations

Applications

- Serve as pulling fittings.
- Provides openings for splicing.
- Connect and change direction of conduit runs.
- When used with a gasket, GS junction boxes are weatherproof.

Features

- Raintight when enclosed and gasketed with hub or blank covers.
- Extra wide mating surfaces of GS box and cover provide greater gasket contact for more positive seal.
- GSU-20 accommodates connection block.
- Universal design — furnished with 4 threaded universal 3/4" hubs, four 3/4" to 1/2" reducers, and three 1/2" close-up plugs.
- Furnished with mounting lugs.
- Cushion fixture hangers are enclosed and gasketed.

Standard Materials





 
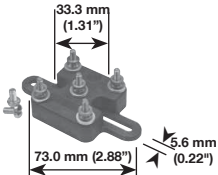
- Conduit outlet boxes, covers and fixture hangers: malleable iron
- Gaskets: neoprene

Standard Finishes

- Malleable iron conduit outlet boxes and covers: triple-coat — (1) zinc electroplate, (2) chromate and (3) epoxy powder coat

NEC Certifications and Compliances

- UL Standard: 514A


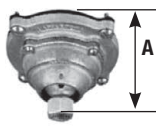
 
	Description	Hub Size (Inches)	Depth in Millimeters (Inches) (A)	Catalog Number
	GS — 1-3/4" Inside Depth, with mounting lugs — Form 20 Four threaded universal 3/4" hubs, four 3/4" to 1/2" reducers, and three 1/2" close-up plugs.	1/2 or 3/4	—	GSU-20
	Four 1" threaded openings and three 1" close-up plugs.	1	—	GSU-100
GS — Cast Covers — Furnished with gasket and screws. Enclosed and gasketed for raintight fit, supports 113.4 kg (250 lb)				
	Hub Cover	1/2 3/4	44.5 (1.75) 44.5 (1.75)	GSK-50-20 GSK-75-20
	Blank Cover	Blank	26.9 (1.06)	GSK-BC-20
	GS — Cover, Lamp Receptacle — Furnished with gasket and screws	—	41.4 (1.63)	GSK-LR20
	GS-20 — Connection Block — Furnished with mounting screws. 5-Wire, 20 A, 300 Volt	—	—	CB205

GS Conduit Outlet Boxes, Covers and Hangers

UNILETS™ for use with Threaded Rigid Metal Conduit and IMC.

NEC:
Rated for Ordinary Locations

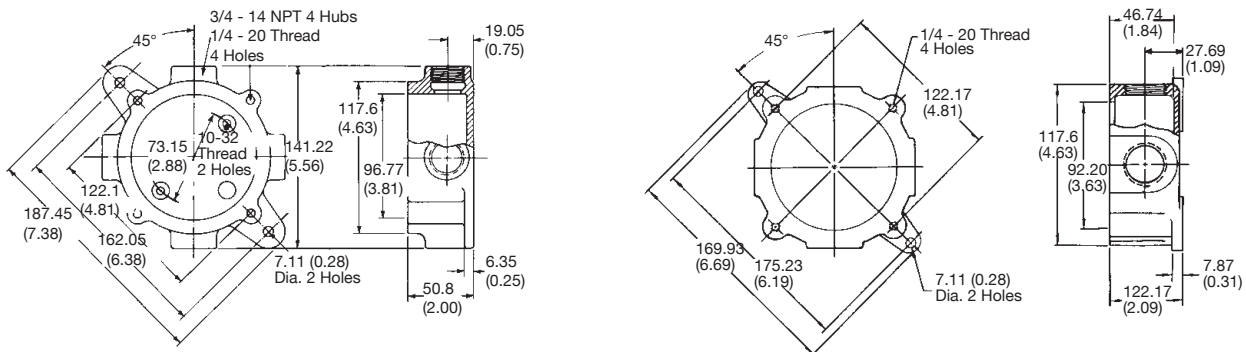
COMMERCIAL AND INDUSTRIAL FITTINGS: CONDUIT OUTLET BODIES

Description	Hub Size (Inches)	Depth in Millimeters (Inches) (A)	Catalog Number
GS — Gasket, Neoprene	—	—	GS-GK20-R
			
GS Flexible Fixture Hangers — Form 20 — Furnished with gasket and screws			
	Ball Type	76.2 (3.00)	GSK-50-20B
	15° swing in all directions, support 113.4 kg (250 lb)	82.6 (3.25)	GSK-75-20B
	Cushion Type	50.8 (2.00)	GSK-50-20C
	Enclosed and gasketed — 8° swing in all directions. Cushions 18.1 kg (40 lb), supports 113.4 kg (250 lb)	50.8 (2.00)	GSK-75-20C

Wiring Capacity

Hub Size (Inches)	Capacity dm ³ (in ³)		
	GS	Hub	GSK Covers
1/2	0.39 (24.00)	0.14 (8.50)	0.14 (8.50)
3/4	0.39 (24.00)	0.14 (8.50)	0.14 (8.50)
1	0.39 (24.00)	0.14 (8.50)	0.14 (8.50)

Dimensions in Millimeters (Inches)



GSU-20
Inside Depth 44.5 mm (1.75")

GSU-100
Inside Depth 44.5 mm (1.75")